


HY15LM Flow Template

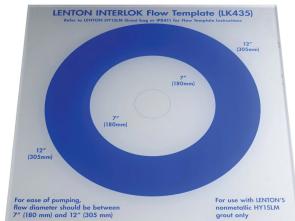

FONCTIONS

Provides minimum and maximum values for the modified slump test

For use with the nVent LENTON Interlok HY15LM Grout

Pre-printed circular target

Durable and reusable


SPÉCIFICATIONS

Table 1/1

Référence catalogue	Matériau	Longueur (L)	Largeur (W)	Poids unitaire
LK435	Plexiglas	381mm	381 mm	0.91 kg

INFORMATIONS PRODUIT COMPLÉMENTAIRES

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

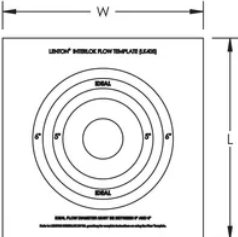

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Option 1 – Customer Care
Option 2 – Technical
Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500

+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Notre gamme complète de marques:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE