

T-Series Horizontal Transition Filler Material Kit



T-Series horizontal filler material kits contain the following: Filler material, two horizontal packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

FONCTIONS

Simplifies ordering

Used to splice different diameter bars

All components are for one-time use

SPÉCIFICATIONS

Table 1/1

Référence catalogue	Taille de barre d'armature, métrique	Taille de barre d'armature, US	Taille de barre d'armature, Canada
RBT89101HB	28 mm, 25 mm	#9, #8	30M, 25M
RBT811101HB	36 mm, 25 mm	#11, #8	35M, 25M
RBT1118101HB	57 mm, 36 mm	#18, #11	55M, 35M
RBT1011101HB	36 mm, 32 mm	#11, #10	

INFORMATIONS PRODUIT COMPLÉMENTAIRES


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBT89101HB	RBF90	RBS354711	RBS5037	RBS5038
RBT811101HB	RBF105	RBS354714	RBS5037	RBS5038
RBT1011101HB	RBF125	RBS354712	RBS5037	RBS5038
RBT1118101HB	RBF240	RBS354712	RBS5037	RBS5039

DIAGRAMMES

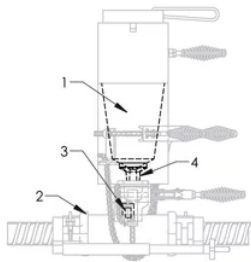

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Notre gamme complète de marques:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

©2025 nVent. Toutes les marques et tous les logos nVent sont la propriété ou sont sous licence de nVent Services GmbH ou de ses sociétés affiliées. Toutes les autres marques déposées sont la propriété de leurs détenteurs respectifs. nVent se réserve le droit de modifier les spécifications sans préavis.