


19" Pusher Fan, 3 U, Axial

Centrale d'électricité

Fan tray with integrated pusher fan.

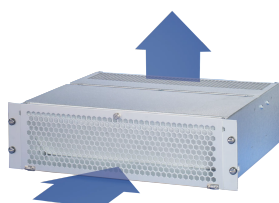

CERTIFICATIONS



CARACTÉRISTIQUES

Ventilation directed accurately to the electronics

19" Pusher Fan, 3 U, Axial

Air infeed from front, air exits at the top rear of cabinet (guided upwards by cover plates or via hoses to rear and upwards)

Contact protection in accordance with DIN EN ISO 13857

LES CARACTÉRISTIQUES TECHNIQUES

Table 1/1

Référence catalogue	Input Voltage AC
10713-546	230 V min
10713-547	115 V min

ADDITIONAL PRODUCT DETAILS

With cover plates, this pusher fan can be re-fitted to different cooling concepts

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : www.nvent.com et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte, une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE