


# Front Panel 2 HP Wide for Combined Mounting

## Centrale d'électricité

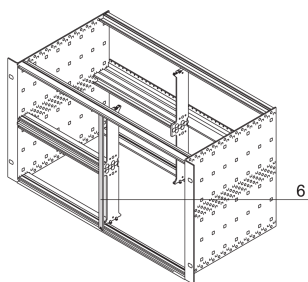

The 2 HP wide front panel covers an open slot. The non-shielded version can be fixed with screws and washers. Due to the 2 HP width, no sleeves can be used.

### CERTIFICATIONS



### CARACTÉRISTIQUES

Flat front panel 6 U, 2 HP, Al, 2.5 mm

### LES CARACTÉRISTIQUES TECHNIQUES

| Table 1/1           |              |             |               |             |                  |
|---------------------|--------------|-------------|---------------|-------------|------------------|
| Référence catalogue | Front Finish | Rear Finish | Treated Edges | Rack Height | Package Quantity |
| 30847-472           | Anodisé      | Conductive  | Non           | 6 U         | 5                |

### ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## AVERTISSEMENT

---

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : [www.nvent.com](http://www.nvent.com) et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte, une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**