


MultipacPRO Front Handle, One-Piece, Width 10 mm

Centrale d'électricité

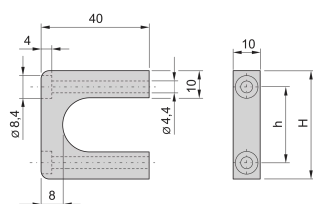

The front handles can be mounted and provide an easier to mount assembly. The handles can be assembled from the front side.

CERTIFICATIONS



CARACTÉRISTIQUES

Load-carrying capacity 30 kg/pair

Assembly on the front panel

Can be used for the aluminium or sheet metal versions

LES CARACTÉRISTIQUES TECHNIQUES

Table 1/2

Référence catalogue	Rack Height	Package Quantity	Handle Type	Couleur	Matériau	Product Family
20860-256	1 U	2	Droit	Silver	Aluminium	MultipacPRO, Frame Type Plug-In Unit
20860-257	2 U	2	Droit	Silver	Aluminium	MultipacPRO, Frame Type Plug-In Unit

Référence catalogue	Rack Height	Package Quantity	Handle Type	Couleur	Matériau	Product Family
20860-258	3 U	2	Droit	Silver	Aluminium	MultipacPRO, Frame Type Plug-In Unit
20860-259	4 U	2	Droit	Silver	Aluminium	MultipacPRO, Frame Type Plug-In Unit
20860-260	5 U	2	Droit	Silver	Aluminium	MultipacPRO, Frame Type Plug-In Unit

Table 2/2

Référence catalogue	Product Type	Largeur	Fonctionne avec
20860-256	Handle	10 mm	Chassis, Front Panels
20860-257	Handle	10 mm	Chassis, Front Panels
20860-258	Handle	10 mm	Chassis, Front Panels
20860-259	Handle	10 mm	Chassis, Front Panels
20860-260	Handle	10 mm	Chassis, Front Panels

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : www.nvent.com et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte, une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE