


CPIW Grounding and Bonding Braid, Stainless Steel for Large Bolts

Power Utilities

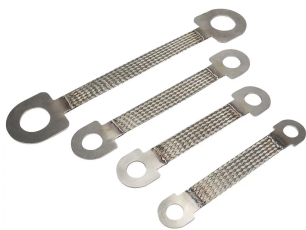

High-quality CPIW stainless steel grounding and bonding braids can be installed in extremely corrosive environments, like offshore applications or coastal applications. The full range of CPIW braids are ideal for applications using stainless steel pipe or tanks, like the food and beverage industry, building industry, transportation, oil and chemical industry.

nVent ERIFLEX offers 316L stainless steel braids, one of the highest resistant stainless steel options on the market. Our proprietary manufacturing process has been optimized to provide the best braiding, welding, and connection palm.

CERTIFICATIONS



FONCTIONS

Superior abrasion, corrosion, chemical and UV resistance make CPIW braids ideal for outdoor applications

Covering from M20 (3/4"-10) up to M42 (1 1/2"-6) bolt fixation point

Great for expansion joints where constant movement requires a flexible and durable solution

Ready to use out of the box, eliminates the need for cutting, stripping, crimping and punching

Quick and easy to install

Resistant to vibration and fatigue, reducing maintenance

Will not rust or discolor, so the appearance will never fade or change

Excellent electrical contact

No additional lugs or terminals needed

Non-magnetic material

 
Recommended by the EMC/EMI directives

Performs to the class C5 (very high) category as per ISO® 12944-2

EAC compliant

RoHS compliant

DIAGRAMMES



AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.



Notre gamme complète de marques:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

©2025 nVent. Toutes les marques et tous les logos nVent sont la propriété ou sont sous licence de nVent Services GmbH ou de ses sociétés affiliées. Toutes les autres marques déposées sont la propriété de leurs détenteurs respectifs. nVent se réserve le droit de modifier les spécifications sans préavis.

Ce document est généré par le système.