


19" Pusher Fan, 3 U, Axial

Power Utilities

Fan tray with integrated pusher fan.

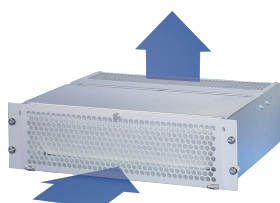

CERTIFICATIONS



FONCTIONS

Ventilation directed accurately to the electronics

19" Pusher Fan, 3 U, Axial

Air infeed from front, air exits at the top rear of cabinet (guided upwards by cover plates or via hoses to rear and upwards)

Contact protection in accordance with DIN EN ISO 13857

SPÉCIFICATIONS

Table 1/1

Référence catalogue	Tension d'entrée CA
10713-546	230 V min
10713-547	115 V min

INFORMATIONS PRODUIT COMPLÉMENTAIRES

With cover plates, this pusher fan can be re-fitted to different cooling concepts

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.



Notre gamme complète de marques:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE