


Front Panel Alternative for Combined Mounting

Power Utilities

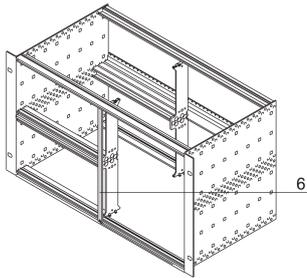

The 2 HP wide front panel covers an open slot. The U-profile front panel can be combined with a textile EMC gasket. It be fixed with screws and washers. Due to the 2 HP width no sleeves can be used.

CERTIFICATIONS



FONCTIONS

U-profile front panel 6 U, 2 HP, Al, 2.5 mm

Prepared for textile EMC gasket

SPÉCIFICATIONS

Table 1/1

Référence catalogue	Finition avant	Face d'appui	Arêtes traitées	Hauteur du rack	Quantité par colis
30849-140	Anodisé	Conducteur	Non	6 U	5

INFORMATIONS PRODUIT COMPLÉMENTAIRES

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.



Notre gamme complète de marques:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE