

CPPS Tapered Plastic Screw-In Plug with Steel Cap for A12



FONCTIONS

Designed for use with the A12 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Steel cap provides added protection from damage

Color coded for the appropriate coupler size

SPÉCIFICATIONS

Table 1/2

Référence catalogue	Référence article	Matériau	Taille de barre d'armature, métrique	Taille de barre d'armature, US	Taille de barre d'armature, Canada	Diamètre (Ø)
EL10CPPS	153600	High Density Polyethylene (HDPE), Acier	10 mm	#3		17 mm
EL12CPPS	153610	High Density Polyethylene (HDPE), Acier	12 mm	#4	10M	17 mm
EL14CPPS	153620	High Density Polyethylene (HDPE), Acier	14 mm			22 mm
EL16CPPS	153630	High Density Polyethylene (HDPE), Acier	16 mm	#5	15M	22 mm


Référence catalogue	Référence article	Matériau	Taille de barre d'armature, métrique	Taille de barre d'armature, US	Taille de barre d'armature, Canada	Diamètre (Ø)
EL18CPPS	153640	High Density Polyethylene (HDPE), Acier	18 mm			27 mm
EL20CPPS	153650	High Density Polyethylene (HDPE), Acier	20 mm	#6	20M	27 mm
EL22CPPS	153660	High Density Polyethylene (HDPE), Acier	22 mm	#7		33 mm
EL25CPPS	153670	High Density Polyethylene (HDPE), Acier	25 mm	#8	25M	33 mm
EL28CPPS	153680	High Density Polyethylene (HDPE), Acier	28 mm	#9	30M	37 mm
EL30CPPS	153690	High Density Polyethylene (HDPE), Acier	30 mm			37 mm
EL32CPPS	153700	High Density Polyethylene (HDPE), Acier	32 mm	#10		42 mm
EL40CPPS	153710	High Density Polyethylene (HDPE), Acier	40 mm			52 mm
EL50TCPPS	154970	High Density Polyethylene (HDPE), Acier	50 mm			64 mm

Table 2/2

Référence catalogue	Référence article	Hauteur (H)	Couleur
EL10CPPS	153600	15 mm	Jaune
EL12CPPS	153610	15 mm	Rouge
EL14CPPS	153620	15 mm	Vert
EL16CPPS	153630	15 mm	Noir
EL18CPPS	153640	15 mm	Blanc

Référence catalogue	Référence article	Hauteur (H)	Couleur
EL20CPPS	153650	15 mm	Jaune
EL22CPPS	153660	18 mm	Bleu
EL25CPPS	153670	18 mm	Rouge
EL28CPPS	153680	18 mm	Noir
EL30CPPS	153690	18 mm	Blanc
EL32CPPS	153700	18 mm	Jaune
EL40CPPS	153710	18 mm	Vert
EL50TCPPS	154970	18 mm	Noir

DIAGRAMMES

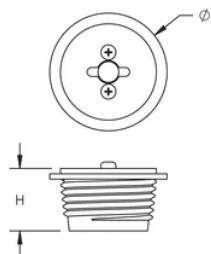

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Notre gamme complète de marques:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE