


Front Panel, U-profile, Refrofit Shielding, 6 U, 84 HP

Centrale d'électricité

RÉFÉRENCE CATALOGUE

20848-189

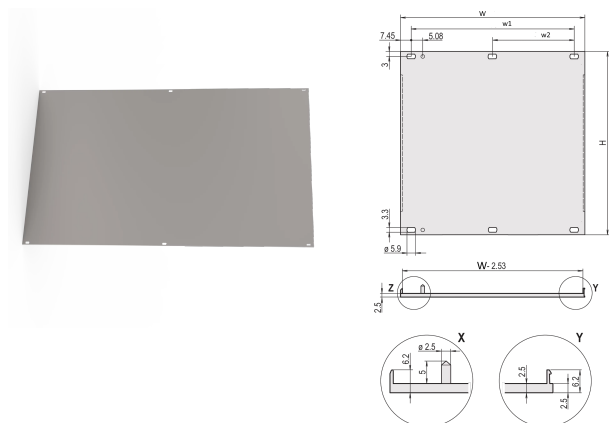

U-profile front panel for textile EMC gasket.

CERTIFICATIONS



CARACTÉRISTIQUES

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

CARACTÉRISTIQUES DU PRODUIT

Product Type: Panneau avant

Type: Front Panel without Handle

Mounting: Screw-on Front

EMC Shielding: No (Retrofittable)

EMC Gasket Type: Textile

Material: Aluminium

Front Finish: Anodisé

Rear Finish: Conductive

Treated Edges: Non

Rack Height: 6 U

Hauteur en mm : 261,8 mm

Rack Width: 84 HP

Largeur en mm : 426,4 mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

14 ... 84 HP: multi-part U-profile (front panel with crimped profiles).

Differences in finish between 2 ... 12 HP and 14 ... 84 HP.

2 ... 12 HP: one-part U-profile

Please order textile EMC gasket separately.

Standard pack quantity: 2 to 28HP: 5 pieces, 42 to 84 HP: 1 piece, supplied in standard pack quantities (SPQ) only.

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : www.nvent.com et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte, une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE