


Frame Type Plug-In Unit PRO Kit, Shielded, Plain Cover, 1 Connector, 6 U, 10 HP, 227 mm

RÉFÉRENCE CATALOGUE

24813-960

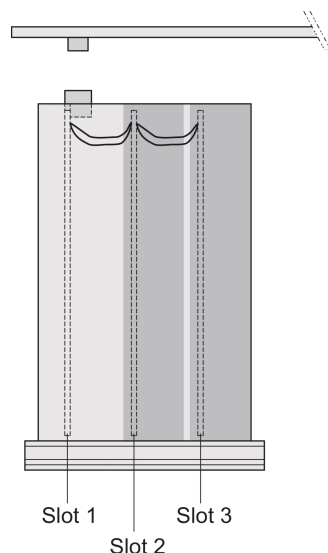

CERTIFICATIONS



FONCTIONS

Rear panel with cut-out for single connector (conforms to EN 60603, DIN 41612, construction types: B, C, D, F, H, Q, R, S)

Extruded side panels with groove to right and left, to insert a PCB (board position in accordance with standard in left side panel only)

Plain cover plates

ATTRIBUTS DU PRODUIT

Type de produit: Cassette

Type: Cassettes PRO

Type de poignée: Trapézoïde

Hauteur du rack: 6 U

Largeur du rack: 10 HP

Profondeur: 227 mm

Blindage électromagnétique: Oui

Type de joint CEM: Textile

Type de panneau arrière: Découpe pour connecteur simple

Type de capot supérieur: Capot supérieur sans perforation

Matériau: Aluminium

Finition avant: Anodisé

Face d'appui: Anodisé

INFORMATIONS PRODUIT COMPLÉMENTAIRES

Guide rails, 2 rear panel retainers and PCB fixing for slot 1 and one slot 2 are already included. Where additional PCBs without rearward connectors are to be fitted, guide rail (part no. 24812-101) and 'PCB fixing from slot 2' (part no. 24812-301 + screw, part no. 24560-178) are also required.

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.



Notre gamme complète de marques:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE