


RackPower iPDU, RP1326, 100-240 VAC, 1-phase

Centrale d'électricité

RÉFÉRENCE CATALOGUE

RP1326

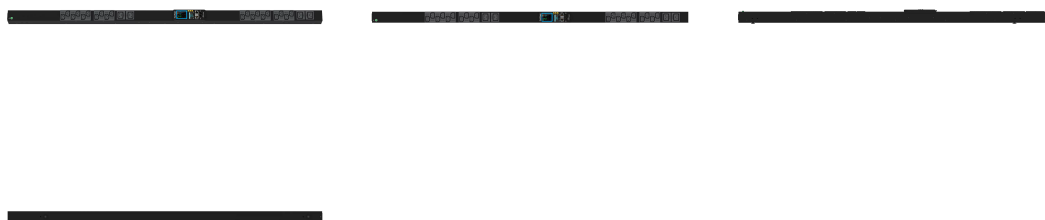

Modular, compact intelligent PDU with inlet metering. Ultra-Low Profile Design with only 44 mm height.

CARACTÉRISTIQUES

RackPower RP1xxx Intelligent Power Distribution Units monitors input power of the entire PDU, provides billing grade unit level monitoring

High Visibility Data Display and Interactive Graphic Display

Measure circuit breaker loads across redundant feeds to avoid accidental downtime

Enables smart load balancing for power efficiency and maximized capacity utilization

Gigabit Ethernet Interface and redundant Ethernet (10/100)

iPDU DC power redundancy solution for up to 64 PDU's

Toolless Hot-Swap Controller

Input Voltage Range 100 - 240 VAC, 1-phase L-N or L-L

Input connector C20

C13, C19 outlets

CARACTÉRISTIQUES DU PRODUIT

Product Type: Socket Strip

Socket Type: IEC C13; IEC C19

Color: Noir

Longueur : 1490 mm

Voltage AC: 208 V

Function: Input Monitored

Profondeur : 53 mm

Largeur en mm : 52 mm

ADDITIONAL PRODUCT DETAILS

Please order bracket for vertical mounting separately.

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : www.nvent.com et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte, une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE