


Poignée d'insertion/extracteur, type IEL, levier noir, bouton-poussoir gris, bas ; 10 pièces

 
RÉFÉRENCE CATALOGUE

20817-612

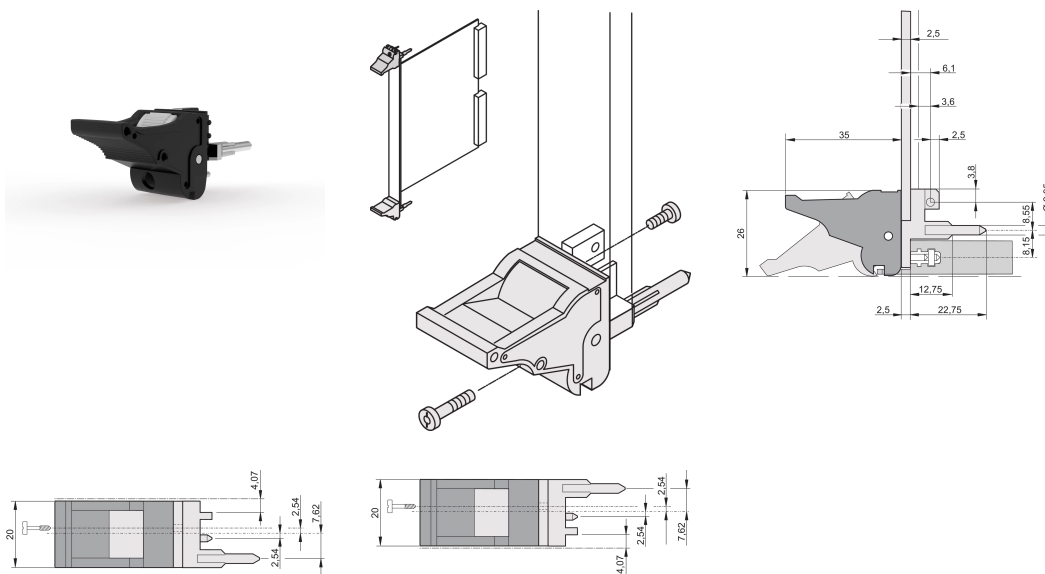

Poignée d'insertion/extraction, de type IEL, conforme IEEE 1101.10, avec décalage 0,1" . Deux poignées peuvent supporter une force de 700 N (par paire).

CERTIFICATIONS



FONCTIONS

Pour des forces d'insertion et d'extraction jusqu'à 700 N (par paire)


Conforme à la norme IEEE 1101.10 et IEC 60297-3-102

Possibilité de monter un microswitch

ATTRIBUTS DU PRODUIT

Quantité par colis: 10

Compatible avec: Faces avant

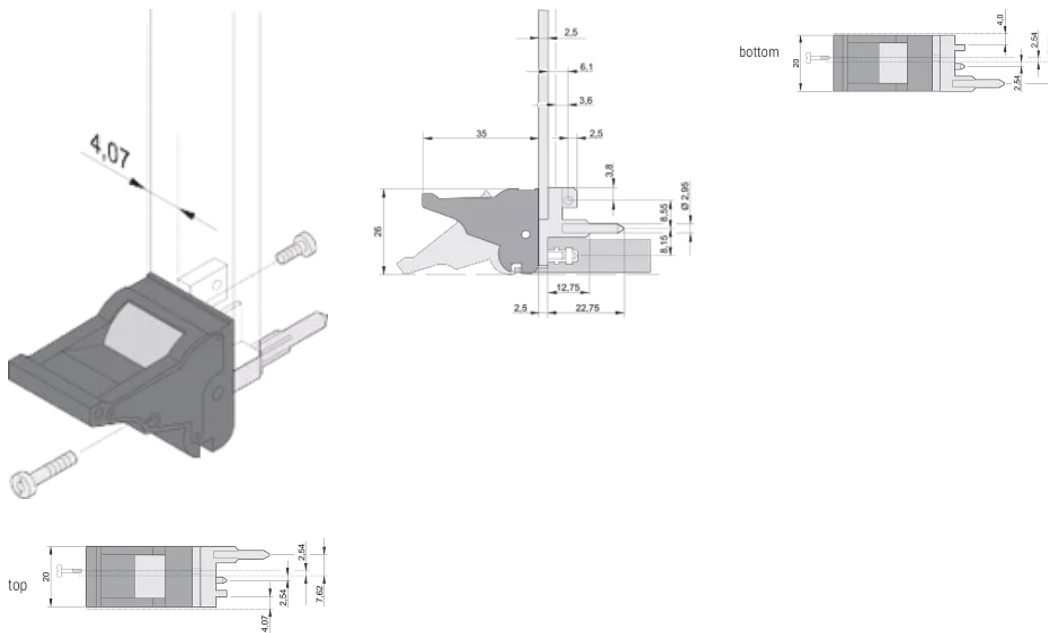

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Notre gamme complète de marques:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE