

B-Series Vertical Filler Material Kit



B-Series vertical filler material kits contain the following: Filler material, vertical packing, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

CARATTERISTICHE

Simplifies ordering

All components are for one-time use

SPECIFICHE

Table 1/1

Codice a catalogo	Dimensioni tondino spirato, unità metriche	Dimensioni tondino spirato, USA	Dimensioni tondino spirato, Canada
RBB1292B	38 mm	#12	
RBB14101B	43 mm	#14	45M
RBB1892B	57 mm	#18	55M
RBB592B	16 mm	#5	15M
RBB692B	20 mm	#6	20M
RBB792B	22 mm	#7	
RBB8101B	25 mm	#8	25M

Codice a catalogo	Dimensioni tondinospiralato, unità metriche	Dimensioni tondinospiralato, USA	Dimensioni tondinospiralato, Canada
RBB992B	28 mm	#9	30M
RBB1092B	32 mm	#10	
RBB11101B	36 mm	#11	35M

INFORMAZIONI DI PRODOTTO AGGIUNTIVE


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBB592B	RBF40	RBS35477	RBS5037	RBS5038
RBB692B	RBF40	RBS35477	RBS5037	RBS5038
RBB792B	RBF50	RBS35478	RBS5037	RBS5038
RBB8101B	RBF55	RBS354710	RBS5037	RBS5038
RBB992B	RBF80	RBS354711	RBS5037	RBS5038
RBB1092B	RBF90	RBS354712	RBS5037	RBS5038
RBB11101B	RBF105	RBS354712	RBS5037	RBS5038
RBB1292B	RBF125	RBS354715	RBS5037	RBS5038
RBB14101B	RBF180	RBS354715	RBS5037	RBS5039
RBB1892B	RBF220	RBS354720	RBS5037	RBS5039

SCHEMI

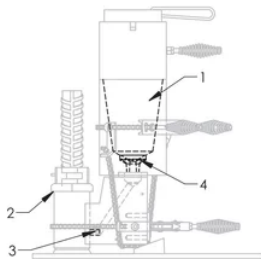

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

Nord America

+1.800.753.9221

Opzione 1 – Assistenza
clienti

Opzione 2 – Assistenza
tecnica

Europa

Paesi Bassi:

+31 800-0200135

Francia:

+33 800 901 793

Europa

Germania:

800 1890272

altri paesi:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Il nostro straordinario portafoglio di marchi:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE