

Giunzione per allineamento finale



End alignment fittings properly locate the sleeve onto the reinforcing steel. The fittings also retain the packing materials and hold them in place, which helps ensure a leak-free installation.

CARATTERISTICHE

Durable, re-usable and long lasting

Easily replaced if damaged

Split-collar design allows for easy installation and removal

SPECIFICHE

Materiale: Acciaio

Table 1/2

Codice a catalogo	Dimensione armatura, metrica	Dimensioni armatura, USA	Dimensioni armatura, Canada	Altezza (H)	Diametro 1 (Ø1)	Diametro 2 (Ø2)
RBM2974125X	20 mm	# 6	20 MLN	64 mm	70 mm	39 mm
RBM2767100E	28 mm	#9	30 MLN	64 mm	70 mm	58 mm
RBM267156K	57 mm	# 18	55 MLN	64 mm	111 mm	87 mm
RBM266975G	43 mm	#14	45 MLN	64 mm	86 mm	76 mm
RBM2870100A	22 mm	# 7		64 mm	70 mm	42 mm

Codice a catalogo	Dimensione armatura, metrica	Dimensioni armatura, USA	Dimensioni armatura, Canada	Altezza (H)	Diametro 1(Ø1)	Diametro 2(Ø2)
RBM2671100M	57 mm	# 18	55 MLN	64 mm	111 mm	96 mm
RBM2687126G	36 mm	#11	35 MLN	64 mm	86 mm	71 mm
RBM2669125J	43 mm	#14	45 MLN	64 mm	86 mm	77 mm
RBM2886112C	25 mm	# 8	25 MLN	64 mm	70 mm	49 mm
RBM2759K	36 mm	#11	35 MLN	64 mm	102 mm	87 mm
RBM2748100D	28 mm	#9	30 MLN	64 mm	70 mm	55 mm
RBM2886150D	25 mm	# 8	25 MLN	64 mm	70 mm	55 mm
RBM2669100H	43 mm	#14	45 MLN	64 mm	86 mm	74 mm
RBM2671125N	57 mm	# 18	55 MLN	64 mm	111 mm	99 mm
RBM275075E	32 mm	# 10		64 mm	70 mm	58 mm
RBM2750125F	32 mm	# 10		64 mm	76 mm	65 mm
RBM267150K	57 mm	# 18	55 MLN	64 mm	111 mm	87 mm
RBM2974100U	20 mm	# 6	20 MLN	64 mm	70 mm	36 mm
RBM266785F	36 mm	#11	35 MLN	64 mm	76 mm	65 mm
RBM267885K	43 mm	#14	45 MLN	64 mm	102 mm	87 mm

Table 2/2

Codice a catalogo	Quantità imballaggio
RBM2974125X	1

Codice a catalogo	Quantità imballaggio
RBM2767100E	1
RBM267156K	1
RBM266975G	1
RBM2870100A	1
RBM2671100M	1
RBM2687126G	1
RBM2669125J	1
RBM2886112C	1
RBM2759K	1
RBM2748100D	1
RBM2886150D	1
RBM2669100H	1
RBM2671125N	1
RBM275075E	1
RBM2750125F	1
RBM267150K	1
RBM2974100U	1
RBM266785F	1

Codice a catalogo	Quantità imballaggio
RBM267885K	1


INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Diameter 2 is the mating surface for the outside diameter of the appropriate sleeve.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

SCHEMI

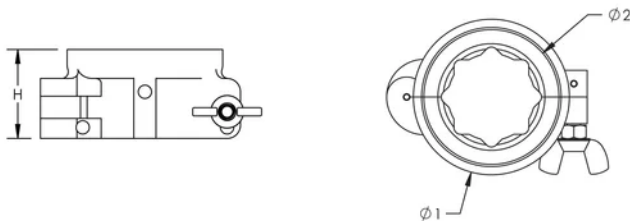

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

Nord America

+1.800.753.9221
Opzione 1 – Assistenza
clienti
Opzione 2 – Assistenza
tecnica

Europa

Paesi Bassi:
+31 800-0200135
Francia:
+33 800 901 793

Europa

Germania:
800 1890272
altri paesi:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE