


# Bacinella di raccolta orizzontale, riempimento laterale, 45°, lato destro

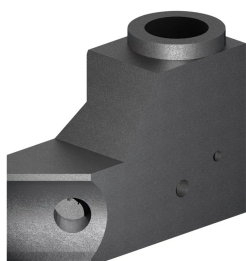

Angular side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

## CARATTERISTICHE

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

## SPECIFICHE

**Materiale:** Grafite

Table 1/2

| Codice a catalogo | Diametro (Ø) | Lunghezza 1 (L1) | Lunghezza 2 (L2) | Larghezza (W) | Altezza 1 (H1) | Altezza 2 (H2) |
|-------------------|--------------|------------------|------------------|---------------|----------------|----------------|
| RBWS2620RHF       | 64 mm        | 141 mm           | 83 mm            | 76 mm         | 154mm          | 76mm           |
| RBWS2620RHM       | 95 mm        | 141 mm           | 83 mm            | 76 mm         | 154mm          | 76mm           |
| RBWS2620RHJ       | 76 mm        | 141 mm           | 83 mm            | 76 mm         | 154mm          | 76mm           |

Table 2/2

| Codice a catalogo | Angolo (a) |
|-------------------|------------|
| RBWS2620RHF       | 45 °       |

| Codice a catalogo | Angolo (a) |
|-------------------|------------|
| RBWS2620RHM       | 45 °       |
| RBWS2620RHJ       | 45 °       |


## INFORMAZIONI DI PRODOTTO AGGIUNTIVE

RBWS2620 pouring basins require one RBW350 and one RBW664 pouring basin frame and one RBS5000 bolt retainer (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## SCHEMI

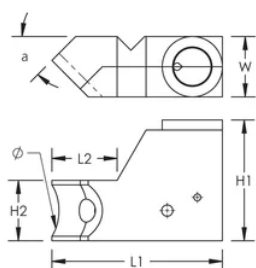

## AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

#### Nord America

+1.800.753.9221

Opzione 1 – Assistenza  
clienti

Opzione 2 – Assistenza  
tecnica

#### Europa

Paesi Bassi:

+31 800-0200135

Francia:

+33 800 901 793

#### Europa

Germania:

800 1890272

altri paesi:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Il nostro straordinario portafoglio di marchi:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**