

Bacinella di raccolta verticale, standard



Standard vertical pouring basins should be used whenever the clearances of the structure allow. The compact size of the standard pouring basins help ensure the best possible flow of filler material.

CARATTERISTICHE

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series vertical sleeves

SPECIFICHE

Materiale: Grafite

Table 1/1

Codice a catalogo	Diametro (Ø)	Lunghezza 1 (L1)	Lunghezza 2 (L2)	Larghezza (W)	Altezza 1 (H1)	Altezza 2 (H2)
RBWS1500U	35 mm	137 mm	38 mm	76 mm	124mm	70mm
RBWS1500X	38 mm	137 mm	38 mm	76 mm	124mm	70mm
RBWS1481F	64 mm	152 mm	38 mm	76 mm	159mm	95mm
RBWS1481G	70 mm	152 mm	38 mm	76 mm	159mm	95mm
RBWS1481H	73 mm	152 mm	38 mm	76 mm	159mm	95mm
RBWS1481J	76 mm	152 mm	38 mm	76 mm	159mm	95mm


Codice a catalogo	Diametro (Ø)	Lunghezza 1 (L1)	Lunghezza 2 (L2)	Larghezza (W)	Altezza 1 (H1)	Altezza 2 (H2)
RBWS1481K	86 mm	152 mm	38 mm	76 mm	159mm	95mm
RBWS1482K	86 mm	165 mm	38 mm	76 mm	191mm	108mm
RBWS1482M	95 mm	165 mm	38 mm	76 mm	191mm	108mm
RBWS1499D	54 mm	149 mm	38 mm	76 mm	140mm	76mm
RBWS1499F	64 mm	149 mm	38 mm	76 mm	140mm	76mm
RBWS1499G	70 mm	149 mm	38 mm	76 mm	140mm	76mm
RBWS1499H	73 mm	149 mm	38 mm	76 mm	140mm	76mm
RBWS1500A	41 mm	137 mm	38 mm	76 mm	124mm	70mm
RBWS1500C	48 mm	137 mm	38 mm	76 mm	124mm	70mm
RBWS1500D	54 mm	137 mm	38 mm	76 mm	124mm	70mm
RBWS1500E	57 mm	137 mm	38 mm	76 mm	124mm	70mm
RBWS1500F	64 mm	137 mm	38 mm	76 mm	124mm	70mm

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

RBWS1481, RBWS1482, RBWS1499 and RBWS1500 pouring basins require one RBM2660 pouring basin frame (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

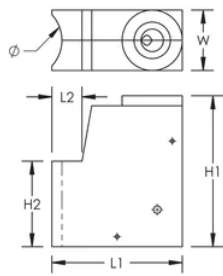

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

Nord America

+1.800.753.9221
Opzione 1 – Assistenza
clienti
Opzione 2 – Assistenza
tecnica

Europa

Paesi Bassi:
+31 800-0200135
Francia:
+33 800 901 793

Europa

Germania:
800 1890272
altri paesi:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE