


Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 6 U, 84 HP

Power Utilities

CODICE A CATALOGO

20848-617

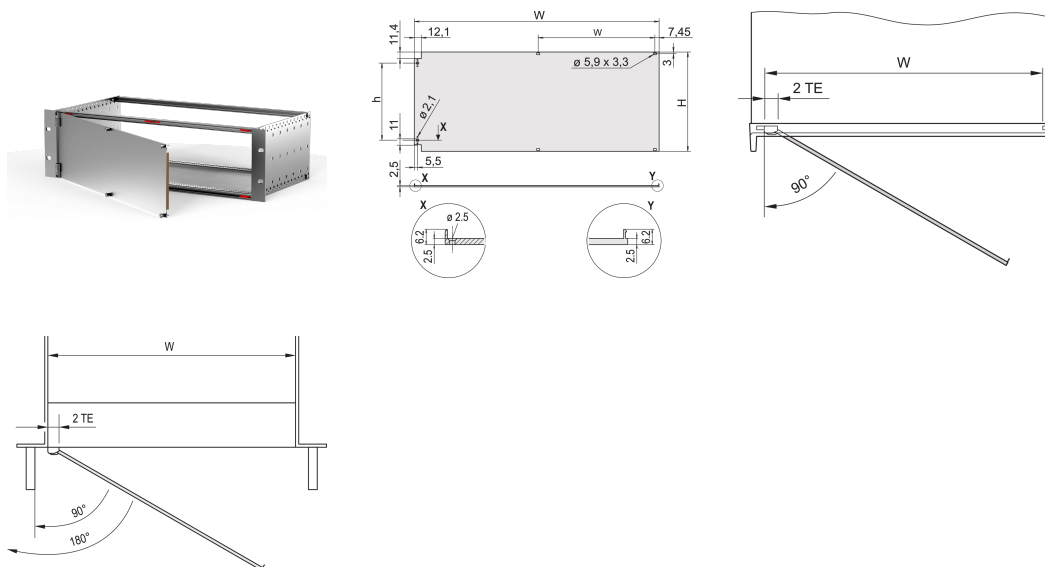

Front panel with textile EMC gasket, side hinged assembly.

CERTIFICAZIONI



CARATTERISTICHE

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

ATTRIBUTI DEL PRODOTTO

Tipo di prodotto: Pannello anteriore

Tipo: Pannello anteriore senza maniglia

Montaggio: Incernierato, laterale

Schermatura EMC: No (adattabile a posteriori)

Tipo di guarnizione: Textile

Materiale: Alluminio

Finitura anteriore: Anodizzato

Finitura posteriore: Conduttivo

Bordi trattati: No

Altezza cremagliera: 6 U

Altezza: 261.8 mm

Larghezza rack: 84 HP

Larghezza: 426.4 mm

Quantità imballaggio: 1

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.



Il nostro straordinario portafoglio di marchi:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE