


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

Servizi di distribuzione di energia

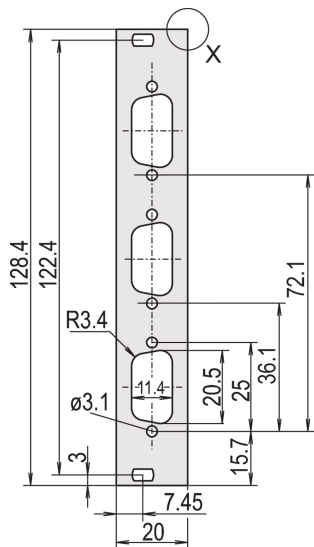

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFICAZIONI



CARATTERISTICHE

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

SPECIFICHE

Table 1/3						
Numero catalogo	Package Quantity	Montaggio	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges

30118-348	5	Screw-on Front	Acciaio inossidabile	Anodized	Conductive	No
30118-349	5	Screw-on Front	Acciaio inossidabile	Anodized	Conductive	No
30118-350	5	Screw-on Front	Acciaio inossidabile	Anodized	Conductive	No
30118-351	5	Screw-on Front	Acciaio inossidabile	Anodized	Conductive	No
30118-352	5	Screw-on Front	Acciaio inossidabile	Anodized	Conductive	No
30118-353	5	Screw-on Front	Acciaio inossidabile	Anodized	Conductive	No
30118-354	5	Screw-on Front	Acciaio inossidabile	Anodized	Conductive	No

Table 2/3						
Numero catalogo	È conforme a	EMC Shielding	Altezza	Materiale	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio	Front Panel	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio	Front Panel	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio	Front Panel	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio	Front Panel	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio	Front Panel	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio	Front Panel	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio	Front Panel	3 U

Table 3/3			
Numero catalogo	Rack Width	Tipo	Larghezza

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVVERTENZA

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito www.nvent.com e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE