


Front Panel, Shielded, Bottom Hinged

Servizi di distribuzione di energia

U-profile front panel bottom hinged for textile gasket.

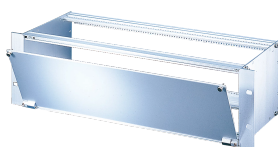

CERTIFICAZIONI



CARATTERISTICHE

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

SPECIFICHE

Table 1/3

Numero catalogo	Rack Height	Rack Width	Package Quantity	Montaggio	EMC Gasket Type	Front Finish
20848-599	3 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-600	3 U	63 HP	1	Hinged, Bottom	Textile	Anodized

Numero catalogo	Rack Height	Rack Width	Package Quantity	Montaggio	EMC Gasket Type	Front Finish
20848-601	3 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-602	6 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-603	6 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-604	6 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-605	4 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-606	4 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-607	4 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-608	3 U	28 HP	1	Hinged, Bottom	Textile	Anodized
20848-696	6 U	28 HP	1	Hinged, Bottom	Textile	Anodized

Table 2/3

Numero catalogo	Rear Finish	Treated Edges	È conforme a	EMC Shielding	Altezza	Materiale
20848-599	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio
20848-600	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio
20848-601	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio
20848-602	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Alluminio
20848-603	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Alluminio
20848-604	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Alluminio

Numero catalogo	Rear Finish	Treated Edges	È conforme a	EMC Shielding	Altezza	Materiale
20848-605	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Alluminio
20848-606	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Alluminio
20848-607	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Alluminio
20848-608	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Alluminio
20848-696	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Alluminio

Table 3/3

Numero catalogo	Product Type	Tipo	Larghezza
20848-599	Front Panel	Front Panel without Handle	213 mm
20848-600	Front Panel	Front Panel without Handle	319.7 mm
20848-601	Front Panel	Front Panel without Handle	426.4 mm
20848-602	Front Panel	Front Panel without Handle	213 mm
20848-603	Front Panel	Front Panel without Handle	319.7 mm
20848-604	Front Panel	Front Panel without Handle	426.4 mm
20848-605	Front Panel	Front Panel without Handle	213 mm
20848-606	Front Panel	Front Panel without Handle	319.7 mm
20848-607	Front Panel	Front Panel without Handle	426.4 mm
20848-608	Front Panel	Front Panel without Handle	141.9 mm

Numero catalogo	Product Type	Tipo	Larghezza
20848-696	Front Panel	Front Panel without Handle	141.9 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

AVVERTENZA

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito www.nvent.com e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE