


# U-profile Front Panel, Shieldable, D-Sub Cutouts

## Servizi di distribuzione di energia

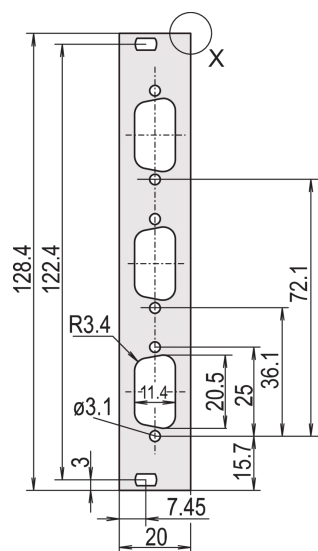

U-profile front panel with cutout for D-Sub connectors.  
Shieldable for textile EMC gasket.

## CERTIFICAZIONI



## CARATTERISTICHE

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

## SPECIFICHE

Table 1/3

| Numero catalogo | Package Quantity | Montaggio      | EMC Gasket Type | Front Finish | Rear Finish | Treated Edges |
|-----------------|------------------|----------------|-----------------|--------------|-------------|---------------|
| 30849-749       | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |

| Numero catalogo | Package Quantity | Montaggio      | EMC Gasket Type | Front Finish | Rear Finish | Treated Edges |
|-----------------|------------------|----------------|-----------------|--------------|-------------|---------------|
| 30849-750       | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-751       | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-752       | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-753       | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-754       | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-755       | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |

Table 2/3

| Numero catalogo | È conforme a                    | EMC Shielding      | Altezza  | Materiale | Product Type | Rack Height |
|-----------------|---------------------------------|--------------------|----------|-----------|--------------|-------------|
| 30849-749       | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio | Front Panel  | 3 U         |
| 30849-750       | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio | Front Panel  | 3 U         |
| 30849-751       | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio | Front Panel  | 3 U         |
| 30849-752       | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio | Front Panel  | 3 U         |
| 30849-753       | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio | Front Panel  | 3 U         |
| 30849-754       | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio | Front Panel  | 3 U         |
| 30849-755       | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio | Front Panel  | 3 U         |

Table 3/3

| Numero catalogo | Rack Width | Tipo | Larghezza |
|-----------------|------------|------|-----------|
|-----------------|------------|------|-----------|

|           |      |                            |       |
|-----------|------|----------------------------|-------|
| 30849-749 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-750 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-751 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-752 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-753 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-754 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-755 | 4 HP | Front Panel without Handle | 20 mm |

## ADDITIONAL PRODUCT DETAILS

---

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## AVVERTENZA

---

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**