


# Metal Connection Kit, Cold-Applied

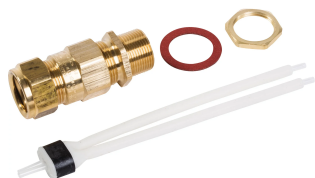

nVent RAYCHEM C25-100-METAL and C3/4-100-METAL are cold-applied metal connection kits for terminating all nVent RAYCHEM self-regulating and power-limiting industrial parallel heating cables to a metal or plastic junction box with internal earthing plate. C25-100-METAL for M25 entries, C3/4-100-METAL: for 3/4" NPT entries.

## CARATTERISTICHE

Simple and fast to install

Cold-applied: core sealing boot with non-curing sealant; no heat gun, no hot work permit needed

One component for all nVent RAYCHEM industrial parallel heating cables

Simplified design in hazardous area, integral part of system approval

Reliable during long life: 10 year extended product warranty available, maintenance free

## SPECIFICHE

|                                  |                            |
|----------------------------------|----------------------------|
| <b>Max Exposure Temperature:</b> | 180 °C                     |
| <b>Tipo di connessione:</b>      | Cold Applied               |
| <b>Model:</b>                    | Connection to Junction Box |

Table 1/1

| Numero catalogo | Nome articolo     | Dimensioni delle filettature |
|-----------------|-------------------|------------------------------|
| 1244-001350     | C3/4-100-METAL-NP | 3/4"                         |
| 440588-000      | C3/4-100-METAL    | 3/4"                         |
| 875016-000      | C25-100-METAL     | M25 x 1.5                    |
| 1244-002296     | C25-100-METAL-NP  | M25 x 1.5                    |

## AVVERTENZA

---

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.

### America del Nord

Tel +1.800.545.6258

Fax +1.800.527.5703

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

### Europe, Middle East, Africa

Tel +32.16.213.511

Fax +32.16.213.604

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

### Asia Pacific

Tel +86.21.2412.1688

Fax +86.21.5426.3167

[cn.thermal.info@nvent.com](mailto:cn.thermal.info@nvent.com)

### America Latina

Tel +1.713.868.4800

Fax +1.713.868.2333

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

Our powerful portfolio of brands:

**RAYCHEM PYROTENAX TRACER NUHEAT**