
 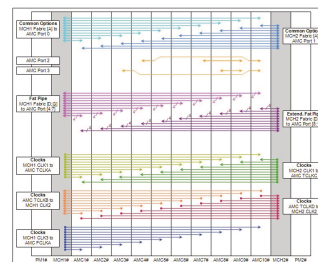


MTCA.0 System for 10 Single Full-Size AMC Modules, 3 U, 84 HP

CODICE A CATALOGO

11850-011



The double AMC card cage on the right hand side can hold either 4 Double Full-size AMCs or, with the optional splitting kit, 8 Single Full-size AMCs.

CERTIFICAZIONI



CARATTERISTICHE

In accordance with PICMG MTCA.0 R1.0 specification

3 U, 19" subrack system for 10 Single Full-Size AdvancedMC modules, 2 Single Full-Size MCHs and 2 power modules with width up to 12 HP

Instead of 8 Single Full-Size AdvancedMC modules, the right-hand board cage can be used for 4 Double Full-Size modules

Backplane with dual star topology, direct connections for S-ATA/SAS

Clock topology to PICMG AMC.0 R2.0

Two hot-swap fan modules in push/pull configuration, each with cooling unit manager (CU EMMC), airflow from right to left

Air filter is front accessible, with presence signal

ATTRIBUTI DEL PRODOTTO

Tipo di prodotto: Sistema

Numero di scanalature: 8

Tipo: Montaggio a rack da 19"

Tipo di backplane: Topologia a doppia stella MTCA.0

Trasferimento dati: 40 GbE; PCIe Gen3

Potenza per slot: 50W

Direzione del flusso d'aria: Da destra a sinistra

Altezza del rack: 3U

Tipo di alimentazione: (2) PM singolo a grandezza naturale

Alimentazione inclusa: No

I/O posteriore: No

È conforme a: PICMG MTCA.0 R2.0

Profondità: 216mm

Altezza: 133.35mm

Quantità nella confezione: 1

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Modified systems available on request.

Completely assembled, wired and tested.

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE