


Pannello anteriore unità plug-in tipo telaio HF, schermatura di ripristino con guarnizione in acciaio, 3 U, 21 CV

CODICE A CATALOGO

20838-097

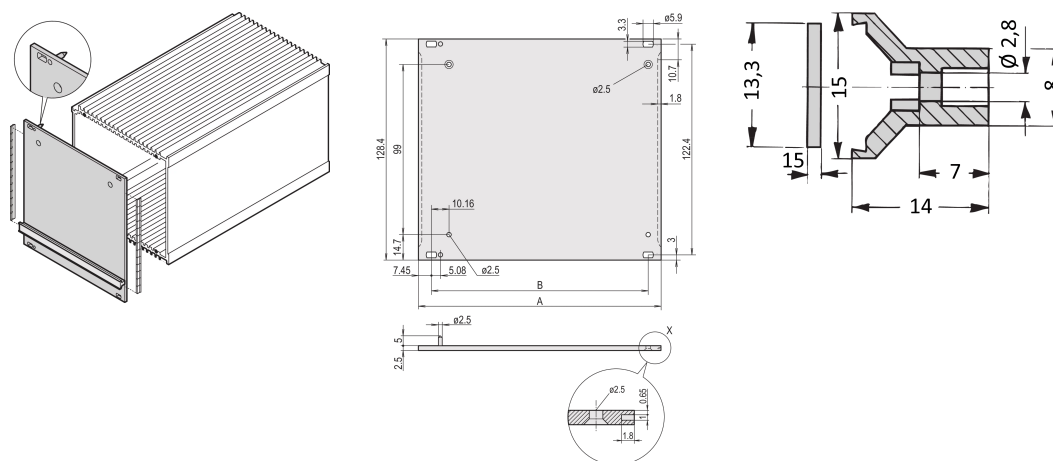

Al, 2,5 mm, anodizzato anteriore, conduttivo posteriore, con fessure laterali per guarnizione EMC in acciaio inox. (Da ordinare separatamente), perno di allineamento pressato; impugnatura a trapezio, grigio, PPE, UL 94 V?1.

CERTIFICAZIONI



CARATTERISTICHE

Al, 2,5 mm, anodizzato anteriore, conduttivo posteriore, con fessure laterali per guarnizione EMC in acciaio inox (da ordinare separatamente), perno di allineamento pressato; impugnatura a trapezio, grigio, DPI, UL 94 V?1

Pannello anteriore con maniglia da imbullonare sull'unità a innesto HF

ATTRIBUTI DEL PRODOTTO

Larghezza rack: 21HP

Quantità imballaggio: 1

Materiale: Alluminio

Altezza cremagliera: 3U

Gross Weight: 0.114kg

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE