


Front Panel Kit, Shielded, Bottom Hinged, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

CODICE A CATALOGO

20848-601

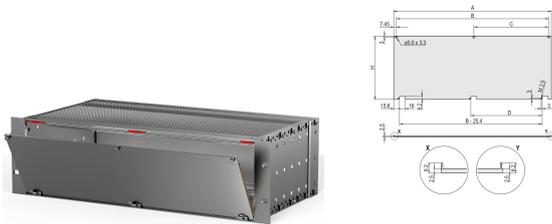

U-profile front panel bottom hinged for textile gasket.

CERTIFICAZIONI



CARATTERISTICHE

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for subracks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

ATTRIBUTI DEL PRODOTTO

Altezza del rack: 3U

Tipo di accessorio: Pannello frontale

Larghezza rack: 84HP

Quantità nella confezione: 1

Montaggio: A cerniera, in basso

Tipo di guarnizione EMC: Tessuto

Finitura anteriore: Anodizzato

Finitura posteriore: Conduttivo

Bordi trattati: No

È conforme a: CODICE 60297-3-101; IEEE 1101,1/10

Profondità (D): 2.5mm

Schermatura EMC: No (installabile in un secondo momento)

Finitura: Anodizzato; Passivato

Altezza (H): 128.4mm

Materiale: Alluminio

Tipo di prodotto: Pannello frontale


Tipo: Pannello frontale senza maniglia

Larghezza (W): 426.4mm

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Front panel can be removed in opened position (> 135°).

SCHEMI

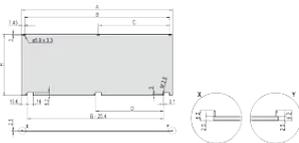

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE