


# Horizontal Rail, Rear, Type H-ST, Heavy, Standard, 42 HP

## CODICE A CATALOGO

**34560-542**

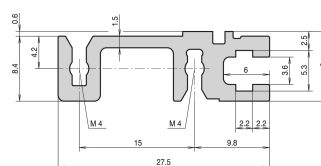

Combinations of horizontal rails and side panels

|                 | 42 HP | 28 HP | 16 HP | 8 HP |
|-----------------|-------|-------|-------|------|
| 42 HP           | +     | +     | +     | +    |
| 28 HP           | +     | +     | +     | +    |
| 16 HP           | +     | +     | +     | +    |
| 8 HP            | +     | +     | +     | +    |
| Horizontal rail | +     | +     | +     | +    |
| Side panel      | +     | +     | +     | +    |

42 HP (not shown)

The horizontal rail, type ST enables the isolated assembly of a backplane. The isolation is done by an insulation strip.

## CERTIFICAZIONI



## CARATTERISTICHE

For indirect backplane mounting with insulation strip

Standard where mechanical demands are high (H-ST)

Mounting top and bottom

< 28 HP not printed

Aluminum extrusion, anodized finish, conductive contact surface, with HP markings

## ATTRIBUTI DEL PRODOTTO

Larghezza rack: 42HP

Quantità nella confezione: 1

Finitura: Anodizzato

Lunghezza: 218.44mm

Materiale: Alluminio

Famiglia di prodotti: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Tipo di prodotto: Guida orizzontale

Tipo: Per impieghi pesanti, ST

Funziona con: Rack secondari; Custodie

## INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Delivery is in standard pack multiples. Pricing is per individual item.

## AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Il nostro straordinario portafoglio di marchi:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE