


EuropacPRO Mounting Plate for Use With Cover Plate

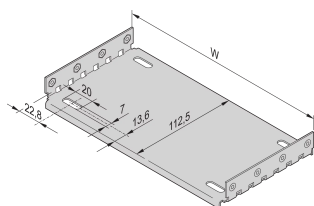

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICAZIONI



CARATTERISTICHE

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

SPECIFICHE

Materiale:	Alluminio
Famiglia di prodotti:	EuropacPRO
Tipo di prodotto:	Piastra di montaggio
Funziona con:	Rack secondari

Table 1/1

Codice a catalogo	Larghezza rack	Quantità nella confezione	Profondità	Larghezza	Certificazioni	Spedizione rapida
-------------------	----------------	---------------------------	------------	-----------	----------------	-------------------

34563-004	84HP	1	112.5mm	431.35mm	RoHS	No
34563-019	63HP	1	172.5mm	324.67mm	RoHS	No
34563-014	42HP	1	172.5mm	217.99mm	RoHS	No
34563-009	28HP	1	172.5mm	146.88mm	RoHS	No
34563-003	63HP	1	112.5mm	324.67mm	RoHS	No
34563-002	42HP	1	112.5mm	217.99mm	RoHS	No
34563-001	28HP	1	112.5mm	146.88mm	RoHS	No
34563-024	84HP	1	172.5mm	431.35mm	RoHS	No
34563-044	84HP	1	412.5mm	431.35mm		No
34563-042	84HP	1	352.5mm	431.35mm		No
34563-028	84HP	1	292.5mm	431.35mm		No
34563-026	84HP	1	232.5mm	431.35mm		No

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE