


Static Handle Plastic in Trapezoid Form, Black

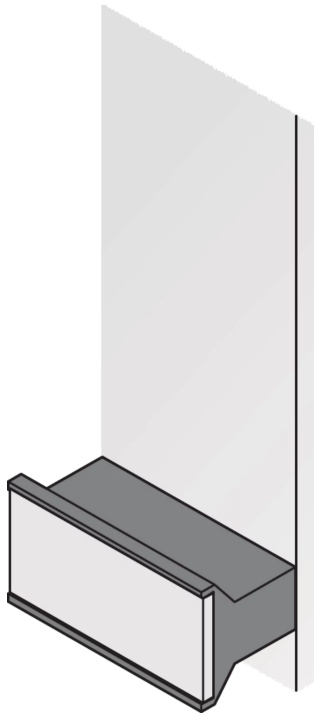

The static plastic handle, trapezoid form in black color can be mounted to a front panel for extraction of the PCB.

CERTIFICAZIONI



CARATTERISTICHE

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPECIFICHE

Funziona con:	Pannelli frontali
Tipo di prodotto:	Manopola
Materiale:	Policarbonato
Tipo:	Statico

Table 1/2

Codice a catalogo	Larghezza rack	Quantità nella confezione	Tipo di maniglia	Classificazione dell'inflammabilità	Colore	È conforme a
20808-080	5HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-081	6HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-082	7HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-083	8HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-084	9HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-085	10HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-086	12HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-087	14HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-088	21HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-089	28HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20808-090	40HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101

Codice a catalogo	Larghezza rack	Quantità nella confezione	Tipo dimaniglia	Classificazione dell'inflammabilità	Colore	È conforme a
20808-091	42HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20809-396	3HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101
20809-397	4HP	1	Trapezoidale, statico	UL® 94V-0	Nero	EN 45545-2, R22-R24, HL3, CODICE 60297-3-101

Table 2/2

Codice a catalogo	Larghezza (W)	Spedizione rapida
20808-080	24mm	No
20808-081	29mm	No
20808-082	34.1mm	No
20808-083	39.2mm	No
20808-084	44.3mm	No
20808-085	49.4mm	No
20808-086	59.6mm	No
20808-087	69.7mm	No
20808-088	105.2mm	No
20808-089	140.8mm	No
20808-090	201.8mm	No
20808-091	212mm	No


Codice a catalogo	Larghezza (W)	Spedizione rapida
20809-396	13.8mm	No
20809-397	18.9mm	No

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

SCHEMI

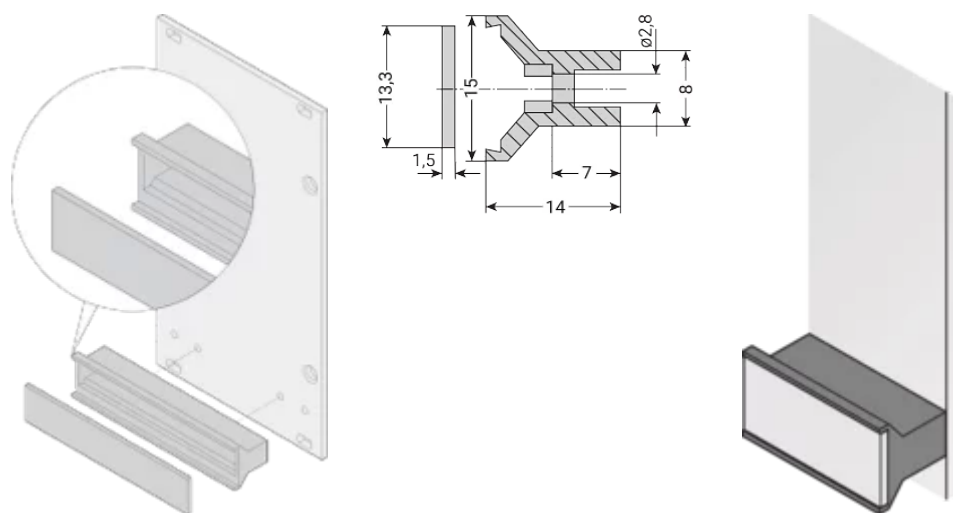

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE