

Bacinella di raccolta orizzontale, riempimento laterale, 45°, lato sinistro



Angular side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

CARATTERISTICHE

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

SPECIFICHE

Materiale: Grafite

Table 1/2

Codice a catalogo	Diametro (Ø)	Lunghezza 1 (L1)	Lunghezza 2 (L2)	Larghezza (W)	Altezza 1 (H1)	Altezza 2 (H2)
RBWS2620LHF	64 mm	141 mm	83 mm	76 mm	154mm	76mm
RBWS2620LHM	95 mm	141 mm	83 mm	76 mm	154mm	76mm
RBWS2620LHJ	76 mm	141 mm	83 mm	76 mm	154mm	76mm

Table 2/2

Codice a catalogo	Angolo (a)
RBWS2620LHF	45 °

Codice a catalogo	Angolo (a)
RBWS2620LHM	45 °
RBWS2620LHJ	45 °


INFORMAZIONI DI PRODOTTO AGGIUNTIVE

RBWS2620 pouring basins require one RBW350 and one RBW664 pouring basin frame and one RBS5000 bolt retainer (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

SCHEMI

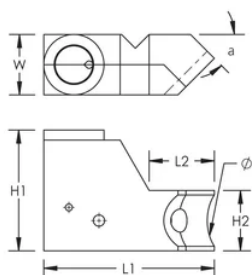

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

Nord America

+1.800.753.9221

Opzione 1 – Assistenza
clienti

Opzione 2 – Assistenza
tecnica

Europa

Paesi Bassi:

+31 800-0200135

Francia:

+33 800 901 793

Europa

Germania:

800 1890272

altri paesi:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Il nostro straordinario portafoglio di marchi:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE