


Combined Mounting Kit for Chassis

Servizi di distribuzione di energia

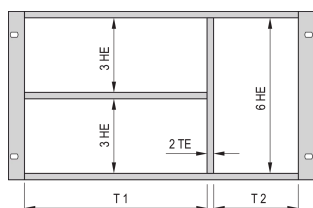

The combined mounting enable the option to split a 6 U high subrack or case in 2 x 3 U and 6 U sections. Different versions are available.

CERTIFICAZIONI



CARATTERISTICHE

Designed to accept Euroboards (100 mm high) and double Euroboards (233.35 mm high)

Subdivision of the 6 U assembly area into: 2 x 3 U, 1 x 6 U

SPECIFICHE

Table 1/2

Numero catalogo	Package Quantity	Rack Width 1	Rack Width 2	Product Family	Product Type	Rack Height
24562-484	1	84 HP		EuropacPRO	Mounting Kit	6 U
24562-420	1	20 HP	62 HP	EuropacPRO	Mounting Kit	6 U
24562-440	1	40 HP	42 HP	EuropacPRO	Mounting Kit	6 U
24562-442	1	42 HP	40 HP	EuropacPRO	Mounting Kit	6 U

Numero catalogo	Package Quantity	Rack Width 1	Rack Width 2	Product Family	Product Type	Rack Height
24562-463	1	63 HP	19 HP	EuropacPRO	Mounting Kit	6 U

Table 2/2

Numero catalogo	Tipo	Works With
24562-484	Combined	Subracks
24562-420	Combined	Subracks
24562-440	Combined	Subracks
24562-442	Combined	Subracks
24562-463	Combined	Subracks

ADDITIONAL PRODUCT DETAILS

Please order separately: Front panel 6 U, 2 HP to cover the strut.

The following guide rails cannot be used: type "accessory", type "accessory, strengthened" and type "for 4.4" PCB".

AVVERTENZA

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito www.nvent.com e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE