


# Front Panel, Flat, Unshielded, D-Sub Cutouts

## Servizi di distribuzione di energia

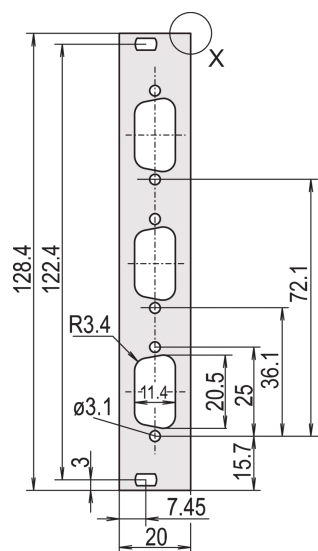

Flat front panel with cutout for D-Sub connectors.  
Unshielded version.

## CERTIFICAZIONI



## CARATTERISTICHE

Non-shielded version

Aluminum, 2.5 mm, front anodized, rear conductive

## SPECIFICHE

Table 1/3

Numero catalogo	Package Quantity	Montaggio	Front Finish	Rear Finish	Treated Edges	È conforme a
30118-341	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10

Numero catalogo	Package Quantity	Montaggio	Front Finish	Rear Finish	Treated Edges	È conforme a
30118-342	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-343	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-344	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-345	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-346	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-347	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10

Table 2/3

Numero catalogo	EMC Shielding	Altezza	Materiale	Product Type	Rack Height	Rack Width
30118-341	No	128.4 mm	Alluminio	Front Panel	3 U	4 HP
30118-342	No	128.4 mm	Alluminio	Front Panel	3 U	4 HP
30118-343	No	128.4 mm	Alluminio	Front Panel	3 U	4 HP
30118-344	No	128.4 mm	Alluminio	Front Panel	3 U	4 HP
30118-345	No	128.4 mm	Alluminio	Front Panel	3 U	4 HP
30118-346	No	128.4 mm	Alluminio	Front Panel	3 U	4 HP
30118-347	No	128.4 mm	Alluminio	Front Panel	3 U	4 HP

Table 3/3

Numero catalogo	Tipo	Larghezza
30118-341	Front Panel without Handle	20 mm

Numero catalogo	Tipo	Larghezza
30118-342	Front Panel without Handle	20 mm
30118-343	Front Panel without Handle	20 mm
30118-344	Front Panel without Handle	20 mm
30118-345	Front Panel without Handle	20 mm
30118-346	Front Panel without Handle	20 mm
30118-347	Front Panel without Handle	20 mm

## ADDITIONAL PRODUCT DETAILS

---

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## AVVERTENZA

---

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**