


# Front Panel, Shielded, Bottom Hinged

## Servizi di distribuzione di energia

U-profile front panel bottom hinged for textile gasket.

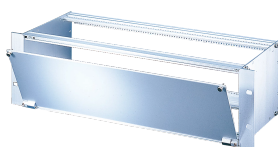

### CERTIFICAZIONI



### CARATTERISTICHE

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

### SPECIFICHE

Table 1/3

| Numero catalogo | Rack Height | Rack Width | Package Quantity | Montaggio      | EMC Gasket Type | Front Finish |
|-----------------|-------------|------------|------------------|----------------|-----------------|--------------|
| 20848-599       | 3 U         | 42 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-600       | 3 U         | 63 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |

| Numero catalogo | Rack Height | Rack Width | Package Quantity | Montaggio      | EMC Gasket Type | Front Finish |
|-----------------|-------------|------------|------------------|----------------|-----------------|--------------|
| 20848-601       | 3 U         | 84 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-602       | 6 U         | 42 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-603       | 6 U         | 63 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-604       | 6 U         | 84 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-605       | 4 U         | 42 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-606       | 4 U         | 63 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-607       | 4 U         | 84 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-608       | 3 U         | 28 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |
| 20848-696       | 6 U         | 28 HP      | 1                | Hinged, Bottom | Textile         | Anodized     |

Table 2/3

| Numero catalogo | Rear Finish | Treated Edges | È conforme a                    | EMC Shielding      | Altezza  | Materiale |
|-----------------|-------------|---------------|---------------------------------|--------------------|----------|-----------|
| 20848-599       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio |
| 20848-600       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio |
| 20848-601       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio |
| 20848-602       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 261.8 mm | Alluminio |
| 20848-603       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 261.8 mm | Alluminio |
| 20848-604       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 261.8 mm | Alluminio |

| Numero catalogo | Rear Finish | Treated Edges | È conforme a                    | EMC Shielding      | Altezza  | Materiale |
|-----------------|-------------|---------------|---------------------------------|--------------------|----------|-----------|
| 20848-605       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 172.9 mm | Alluminio |
| 20848-606       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 172.9 mm | Alluminio |
| 20848-607       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 172.9 mm | Alluminio |
| 20848-608       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Alluminio |
| 20848-696       | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 261.8 mm | Alluminio |

Table 3/3

| Numero catalogo | Product Type | Tipo                       | Larghezza |
|-----------------|--------------|----------------------------|-----------|
| 20848-599       | Front Panel  | Front Panel without Handle | 213 mm    |
| 20848-600       | Front Panel  | Front Panel without Handle | 319.7 mm  |
| 20848-601       | Front Panel  | Front Panel without Handle | 426.4 mm  |
| 20848-602       | Front Panel  | Front Panel without Handle | 213 mm    |
| 20848-603       | Front Panel  | Front Panel without Handle | 319.7 mm  |
| 20848-604       | Front Panel  | Front Panel without Handle | 426.4 mm  |
| 20848-605       | Front Panel  | Front Panel without Handle | 213 mm    |
| 20848-606       | Front Panel  | Front Panel without Handle | 319.7 mm  |
| 20848-607       | Front Panel  | Front Panel without Handle | 426.4 mm  |
| 20848-608       | Front Panel  | Front Panel without Handle | 141.9 mm  |

| Numero catalogo | Product Type | Tipo                       | Larghezza |
|-----------------|--------------|----------------------------|-----------|
| 20848-696       | Front Panel  | Front Panel without Handle | 141.9 mm  |

## ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

## AVVERTENZA

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**