


Die Cast Foot

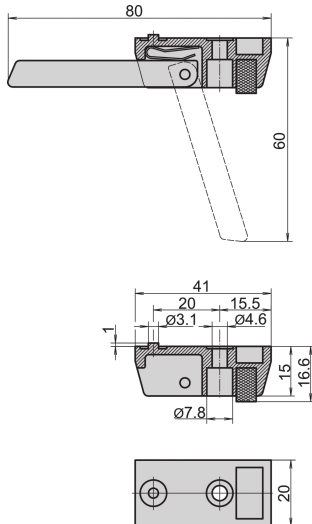

The tip-up feet from aluminum die cast material enable mounting on the bottom plate of a case. Available with or without tip-up function. Color RAL 9006 White Aluminum.

CERTIFICAZIONI



CARATTERISTICHE

Positioning of case is secured by anti-slip rubber inserts

Can be used instead of standard feet

Load-carrying capacity: 50 kg per foot, max case weight 40 kg

Mounting holes are provided in bottom cover of the cases

SPECIFICHE

Materiale:	Alluminio
Funziona con:	Custodie
Famiglia di prodotti:	RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac
Tipo di prodotto:	Pedale
Colore:	Argento

Table 1/1

Codice a catalogo	Quantità nella confezione	Codice colore	Tipo	Spedizione rapida
10603-001	1	RAL 9006	Pedale, Senza ribaltamento	No
10603-002	1	RAL 9006	Pedale, Con ribaltamento	No

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE