


Front Panel EMC Textile Shielding Kit, -40... +70°C, 3 U; 10 pieces

CODICE A CATALOGO

21101-853

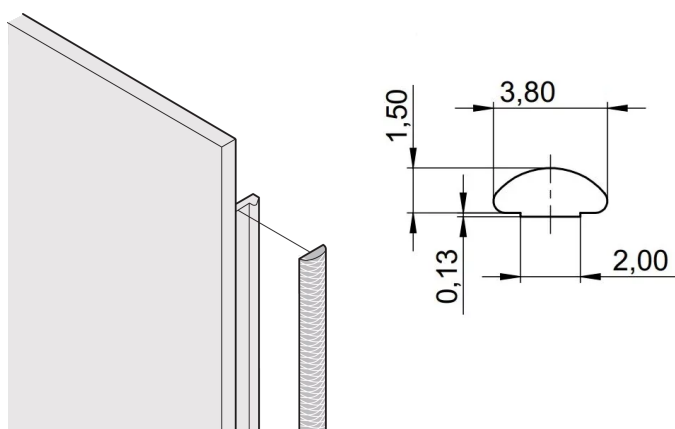

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel.

CERTIFICAZIONI



CARATTERISTICHE

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +70 °C

ATTRIBUTI DEL PRODOTTO

Altezza del rack: 3U

Quantità nella confezione: 10

Profondità (D): 1.62mm

Altezza (H): 97mm

Materiale: Elastomero termoplastico

Famiglia di prodotti: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Unità a innesto di tipo profilato

Tipo di prodotto: Kit di schermatura

Larghezza (W): 3.8mm


Funziona con: Rack secondari; Custodie; Pannelli frontali

Classificazione dell'infiammabilità: UL® 94V-0

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

EMC gaskets (textile) are required for shielding the front panels.

SCHEMI

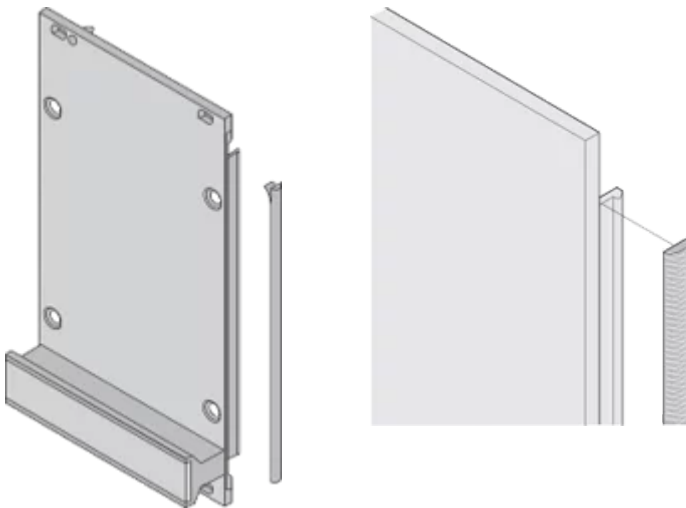

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE