


Kit di messa a terra PropacPRO

CODICE A CATALOGO

21102-001

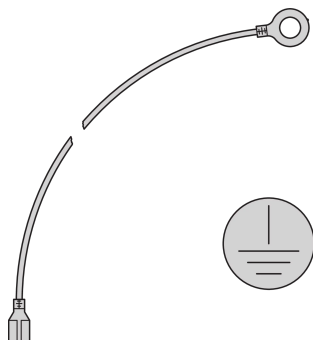

Collegamenti GND/messa a terra protettivi conformi a: DIN EN 50178, VDE 0160 DIN EN 62368-1, VDE 0805 DIN EN 61010?1, VDE 0411 PARTE 1 DIN EN 61010?1A2, VDE 0411 PARTE 1/A1.

CERTIFICAZIONI



CARATTERISTICHE

Collegamenti GND/messa a terra protettivi conformi a: DIN EN 50178/VDE 0160 DIN EN 62368-1/VDE 0805 DIN EN 61010?1 /VDE 0411 PARTE 1 DIN EN 61010?1A2 /VDE 0411 PARTE 1/A1

Testato VDE

DIN EN 50178/VDE 0160DIN EN 62368-1/VDE 0805 DIN EN 61010?1/VDE 0411 PARTE 1DIN EN 61010?1A2/VDE 0411 PARTE 1A1

ATTRIBUTI DEL PRODOTTO

Tipo di prodotto: Kit di messa a terra

Famiglia di prodotti: PropacPRO

Tipo: Kit di messa a terra

Funziona con: Casi

Quantità imballaggio: 1

Net Weight: 0.03kg

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE