


EuropacPRO 19" Subrack Kit for Backplane, Shielded, 3 U, 415 mm

CODICE A CATALOGO

24563-145

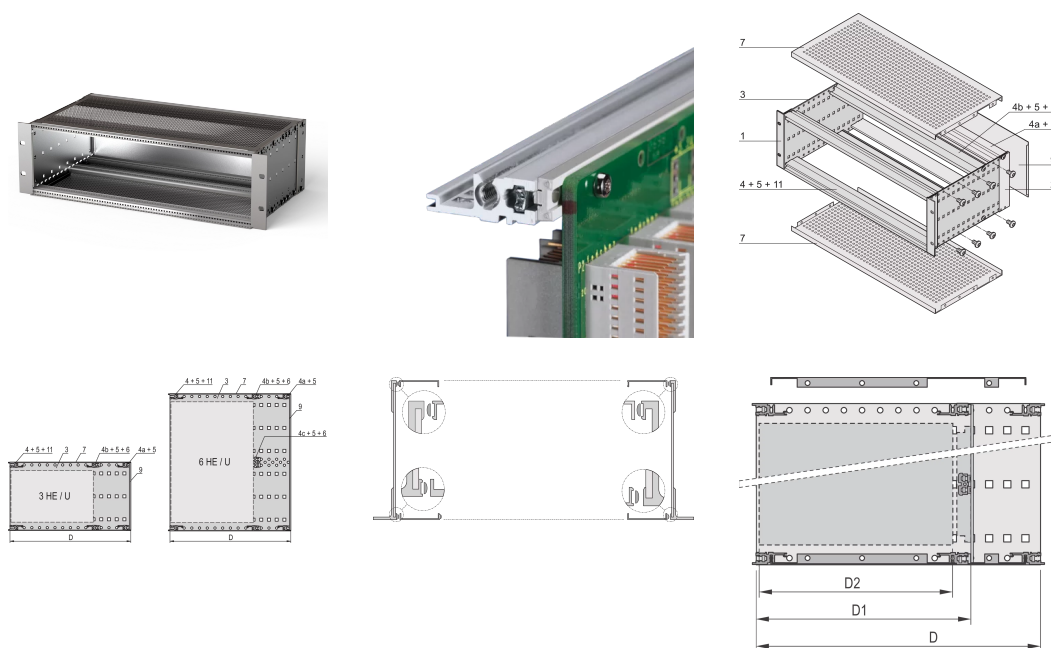

EMC Shielded subrack for backplane mounting, rear side covered by a rear panel.

CERTIFICAZIONI



CARATTERISTICHE

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Aluminum construction

Rear horizontal rail for backplane mounting with insulation strip

Horizontal rail type "light"

Altezza del rack: 3U

Profondità (D): 415mm

Quantità nella confezione: 1

Per il montaggio: Backplane

Profondità scheda: 160mm; 220mm; 280mm

Tipo di guarnizione EMC: Tessuto

Maniglia in dotazione: No

Montaggio: Rack

È conforme a: CODICE 60297-3-103

Schermatura EMC: Sì

Finitura: Anodizzato; Passivato

Materiale: Alluminio

Tipo di prodotto: Rack secondario/Telaio

Larghezza rack: 84HP

Carico statico: 11kg

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

Diagram illustrating the exploded view of a 2x2x2 cube structure, showing dimensions and assembly components:

- Top face dimensions: $4 \times 5 + 11$ (left), $4 \times 5 + 6$ (right).
- Front face dimensions: 4×5 (left), $4 \times 5 + 6$ (right).
- Bottom face dimensions: $4 \times 5 + 11$ (left).
- Labels 1 through 10 indicate specific assembly components or steps.

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle

istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE