


# CPCI System With ATX PSU, 3 U, 8 Slot

## CODICE A CATALOGO

**24579-031**

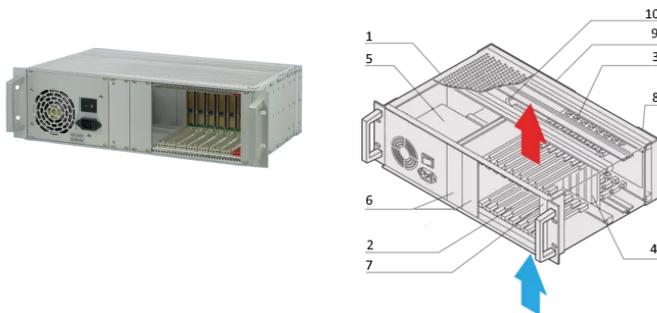

Fanless 3U CompactPCI System with vertical Card Cage for eight 3U Boards and eight RTM Boards. With built in ATX Power Supply.

## CERTIFICAZIONI



## CARATTERISTICHE

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with vertical card cage. Board format Front: 3 U, 160 mm deep; Rear I/O: 3 U, 80 mm deep

Backplane 8 slot, 3 U, 32 bit; system slot right; 8 HP wide CPU can be used

Heat dissipation by convection, airflow bottom to top

ATX PSU, 300 W

## ATTRIBUTI DEL PRODOTTO

Tipo di prodotto: Sistema

Numero di scanalature: 8

Tipo: Montaggio a rack da 19"

Tipo di backplane: 3 U CompactPCI

Trasferimento dati: Bus PCI a 32 bit

Potenza per slot: 10W

Tensione di ingresso CA: 100 – 240V

Altezza del rack: 3U

Tipo di alimentazione: (1) ATX PSU

Alimentazione inclusa: Sì

I/O posteriore: Sì

È conforme a: PICMG 2.0 R3.0

Profondità: 275mm

Altezza: 132.55mm

Quantità nella confezione: 1

## INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Modified systems available on request.

## AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Il nostro straordinario portafoglio di marchi:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**