


Front Panel EMC Stainless Steel Shielding Kit

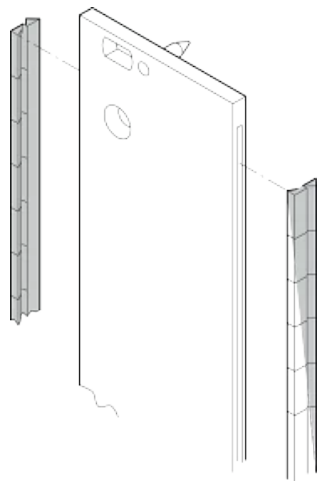

The stainless steel EMC gaskets are inserted into the lateral slots of the shieldable front panels (2 pieces per front panel).

CERTIFICAZIONI



CARATTERISTICHE

The stainless steel EMC gaskets are inserted into the lateral slots of the shieldable front panels (2 pieces per front panel)

EMC contact strip, stainless steel

Temperature range -200 °C ... +160 °C

SPECIFICHE

Funziona con:	Rack secondari; Custodie; Pannelli frontali
Famiglia di prodotti:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Unità a innesto di tipo profilato
Tipo di prodotto:	Kit di schermatura
Materiale:	Acciaio inossidabile


Table 1/1

Codice a catalogo	Altezza del rack	Quantità nella confezione	Profondità (D)	Altezza (H)	Larghezza (W)	Spedizione rapida
-------------------	------------------	---------------------------	----------------	-------------	---------------	-------------------

21101-775	2U	10	2.22mm	52mm	4.97mm	No
21101-776	2U	100				No
21101-705	3U	10	2.22mm	97mm	4.97mm	No
21101-707	6U	10	2.22mm		4.97mm	No
21101-706	3U	100	2.22mm	97mm	4.97mm	No
21101-709	9U	10	2.22mm		4.97mm	No
21101-713	4U	10	2.22mm	142mm	4.97mm	No
21101-714	4U	100				No
21101-777	5U	10				No
21101-778	5U	100				No
21101-708	6U	100				No
21101-710	9U	100				No

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Please order assembly tool separately.

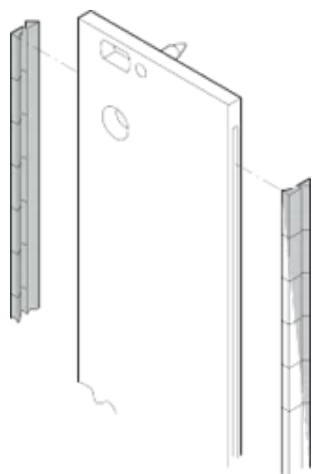

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE