


# Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

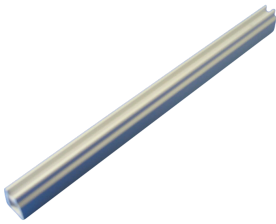

## CARATTERISTICHE

Middle profile for mounting guide rails for 2.5 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

## SPECIFICHE

Table 1/2

| Codice a catalogo | Profondità scheda | Colore  | Finitura   | Larghezza scanalatura | Materiale | Quantità nella confezione |
|-------------------|-------------------|---------|------------|-----------------------|-----------|---------------------------|
| 34562-822         | 1000mm            | Argento | Anodizzato | 2.5                   | Alluminio | 1                         |
| 34562-814         | 220mm             | Argento | Anodizzato | 2.5                   | Alluminio | 1                         |
| 34562-815         | 280mm             | Argento | Anodizzato | 2.5                   | Alluminio | 1                         |
| 34562-813         | 160mm             | Argento | Anodizzato | 2.5                   | Alluminio | 1                         |
| 34562-816         | 340mm             | Argento | Anodizzato | 2.5                   | Alluminio | 1                         |

Table 2/2

| Codice a catalogo | Tipo             | Funziona con                     | Spedizione rapida |
|-------------------|------------------|----------------------------------|-------------------|
| 34562-822         | Sezione centrale | Rack secondari, Custodie, Telaio | No                |
| 34562-814         | Sezione centrale | Rack secondari, Custodie, Telaio | No                |
| 34562-815         | Sezione centrale | Rack secondari, Custodie, Telaio | No                |
| 34562-813         | Sezione centrale | Rack secondari, Custodie, Telaio | No                |
| 34562-816         | Sezione centrale | Rack secondari, Custodie, Telaio | No                |

## INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte o/o annullare la vostra garanzia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Il nostro straordinario portafoglio di marchi:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**