


Socket Strip, IEC C19

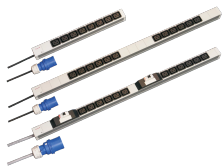

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with IEC C19 outlets.

CERTIFICAZIONI



CARATTERISTICHE

Socket strips with C19 IEC sockets

Socket strips can be rotated through all four directions (in 90° increments) during installation

Connecting cable 2 m, with connector in accordance with IEC 60309

Mounting height 1 U

SPECIFICHE

Materiale: Alluminio; Poliammide
Colore: Grigio
Tipo di prodotto: Multipresa

Table 1/2

Codice a catalogo	Tipo di presa	Quantità di prese	Prese commutate	Tensione CA	Quantità nella confezione	Profondità
60110-280	IEC C19	8	No	230V	1	44mm
60110-282	IEC C19	12	No	230V	1	44mm

Codice a catalogo	Tipo di presa	Quantità di prese	Prese commutate	Tensione CA	Quantità nella confezione	Profondità
60110-281	IEC C19	12	No	230V	1	44mm

Table 2/2

Codice a catalogo	Finitura	Altezza	Lunghezza	Spedizione rapida
60110-280	Anodizzato	44mm	438.5mm	No
60110-282	Anodizzato	44mm	947.5mm	No
60110-281	Anodizzato	44mm	947.5mm	No

INFORMAZIONI DI PRODOTTO AGGIUNTIVE

Please order bracket for vertical mounting separately.

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Il nostro straordinario portafoglio di marchi:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE