

Hydraulic nVent ERIFLEX Flexibar Shearing Tool



CERTIFICERINGEN



KENMERKEN

RoHS-conform

Cuts nVent ERIFLEX Flexibar quickly and accurately without burrs or deformation

Cuts through the insulation without damaging it

Works with all sizes of nVent ERIFLEX Flexibar

Clear plastic shields allow for visual inspection of cutting position

Strong mechanical assembly

Replacement blade available

SPECIFICATIES


Table 1/1

Catalogusnummer	Artikelnummer	Diepte (D)	Hoogte (H)	Breedte (W)	Gewicht eenheid
HYDR-FLEX-ST	559010	240mm	341 mm	280 mm	34 kg

AANVULLENDE PRODUCTGEGEVENS

Nicht zum Schneiden von festen Verteilerschienen verwenden.

DIAGRAMMEN

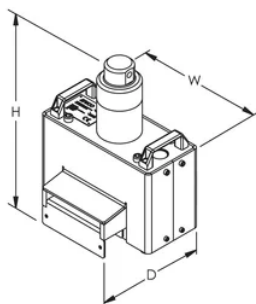

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische

ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE