

Kit met verticaal vulmateriaal uit de B-serie



B-Series vertical filler material kits contain the following: Filler material, vertical packing, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

KENMERKEN

Simplifies ordering

All components are for one-time use

SPECIFICATIES

Table 1/1

Catalogusnummer	Grootte rebar, metrisch	Formaat wapening, VS	Formaat rebar, Canada
RBB1292B	38 mm	#12	
RBB14101B	43 mm	#14	45M
RBB1892B	57 mm	#18	55M
RBB592B	16 mm	#5	15M
RBB692B	20 mm	#6	20M
RBB792B	22 mm	#7	
RBB8101B	25 mm	#8	25M
RBB992B	28 mm	#9	30M

Catalogusnummer	Grootte rebar, metrisch	Formaat wapening, VS	Formaat rebar, Canada
RBB1092B	32 mm	#10	
RBB11101B	36 mm	#11	35M

AANVULLENDE PRODUCTGEGEVENS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBB592B	RBF40	RBS35477	RBS5037	RBS5038
RBB692B	RBF40	RBS35477	RBS5037	RBS5038
RBB792B	RBF50	RBS35478	RBS5037	RBS5038
RBB8101B	RBF55	RBS354710	RBS5037	RBS5038
RBB992B	RBF80	RBS354711	RBS5037	RBS5038
RBB1092B	RBF90	RBS354712	RBS5037	RBS5038
RBB11101B	RBF105	RBS354712	RBS5037	RBS5038
RBB1292B	RBF125	RBS354715	RBS5037	RBS5038
RBB14101B	RBF180	RBS354715	RBS5037	RBS5039
RBB1892B	RBF220	RBS354720	RBS5037	RBS5039

DIAGRAMMEN

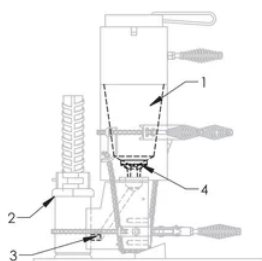

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent

klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische

ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE