

Horizontal gietbassin, zijvulling, uitgeschoven



Extended side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

KENMERKEN

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

SPECIFICATIES

Materiaal: Grafiet

Table 1/1

Catalogusnummer	Diameter (Ø)	Lengte 1 (L1)	Lengte 2 (L2)	Breedte (W)	Hoogte 1 (H1)	Hoogte 2 (H2)
RBHSA9750X	38 mm	248 mm	38 mm	76 mm	127mm	76mm
RBHSB10560X	38 mm	267 mm	38 mm	76 mm	152mm	76mm
RBHSB12065X	38 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSA9050D	54 mm	229 mm	38 mm	76 mm	127mm	76mm
RBHSA9050F	64 mm	229 mm	38 mm	76 mm	127mm	76mm
RBHSA9560M	95 mm	241 mm	38 mm	76 mm	152mm	76mm

Catalogusnummer	Diameter (Ø)	Lengte 1 (L1)	Lengte 2 (L2)	Breedte (W)	Hoogte 1 (H1)	Hoogte 2 (H2)
RBHSB12065C	48 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065F	64 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065J	76 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065M	95 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB14065F	64 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14065J	76 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14070D	54 mm	356 mm	38 mm	76 mm	178mm	76mm
RBHSB14075M	95 mm	356 mm	38 mm	76 mm	191mm	76mm
RBHSB16070F	64 mm	406 mm	38 mm	76 mm	178mm	76mm
RBHSB17070C	48 mm	432 mm	38 mm	76 mm	178mm	76mm
RBHSB177550M	95 mm	451 mm	38 mm	76 mm	127mm	76mm
RBHSC23010M	95 mm	584 mm	38 mm	76 mm	254mm	76mm
RBHSC23075M	95 mm	584 mm	38 mm	76 mm	191mm	76mm
RBHSC30070D	54 mm	762 mm	38 mm	76 mm	191mm	76mm


AANVULLENDE PRODUCTGEGEVENS

RBHSA pouring basins require one RBW332 pouring basin frame and two RBS5000 bolt retainers. RBHSB pouring basins require one RBW3321 pouring basin frame and one RBS5000 bolt retainer. RBHSC pouring basins require one RBW3322 pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMMEN

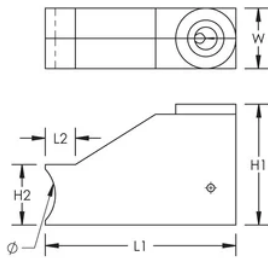

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221
optie 1 – Klantenservice
optie 2 – Technische
ondersteuning

Europa

Nederland:
+31 800-0200135
Frankrijk:
+33 800 901 793

Europa

Duitsland:
800 1890272
andere landen:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE