


P24 Position Coupler

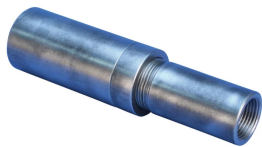

The P24 family of position couplers is designed for use on ASTM A615 grade 100 (700 MPa) reinforcing steel. The performance of the spliced connection is designed to meet the bars' specified ultimate tensile strength of 115 ksi (792 MPa).

KENMERKEN

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

SPECIFICATIES

Afwerking:	Onbewerkt
Materiaal:	Staal
100% Amerikaanse inhoud:	Ja

Table 1/2

Catalogusnummer	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Diameter (Ø)	Lengte 1 (L1)	Lengte 2 (L2)
EL22P24L	22 mm	#7		44 mm	172 mm	188 mm
EL25P24L	25 mm	#8	25M	48 mm	183 mm	199 mm
EL28P24L	28 mm	#9	30M	57 mm	192 mm	208 mm
EL32P24L	32 mm	#10		60 mm	208 mm	224 mm
EL36P24L	36 mm	#11	35M	70 mm	227 mm	243 mm

Catalogusnummer	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Diameter (Ø)	Lengte 1 (L1)	Lengte 2 (L2)
EL43TP24L	43 mm	#14	45M	80 mm	296 mm	324 mm
EL57TP24L	57 mm	#18	55M	102 mm	347 mm	375 mm


Table 2/2

Catalogusnummer	Stangdiepte (BD)	Tussenruimte stang 1 (BG1)	Tussenruimte stang 2 (BG2)	Koppelingshuis (CB)	Gewicht eenheid
EL22P24L	37mm	98mm	114mm	92mm	1.55 kg
EL25P24L	40mm	103mm	119mm	98mm	1.87 kg
EL28P24L	42mm	108mm	124mm	104mm	2.85 kg
EL32P24L	45mm	118mm	134mm	110mm	3.39 kg
EL36P24L	52mm	124mm	140mm	120mm	5.1 kg
EL43TP24L	66mm	164mm	192mm	160mm	8.3 kg
EL57TP24L	83mm	180mm	208mm	188mm	15.5 kg

AANVULLENDE PRODUCTGEGEVENS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMMEN

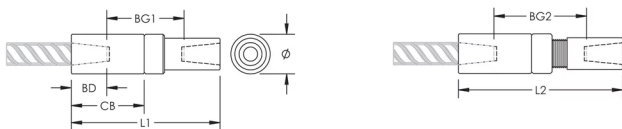

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en

waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221
optie 1 – Klantenservice
optie 2 – Technische
ondersteuning

Europa

Nederland:
+31 800-0200135
Frankrijk:
+33 800 901 793

Europa

Duitsland:
800 1890272
andere landen:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

©2025 nVent. Alle nVent-merken en -logo's zijn eigendom van of in licentie gegeven door nVent Services GmbH of haar gelieerde ondernemingen. Alle andere handelsmerken zijn het eigendom van hun respectieve eigenaren. nVent behoudt zich het recht voor om specificaties zonder kennisgeving te wijzigen.

Dit document is door het systeem gegenereerd.