

Installatieapparatuur voor horizontale transitie van de T-serie



T-Series horizontal installation equipment kits contain the following: Pouring basin frame, crucible frame set (crucible chain assembly, crucible extension, crucible cover), two end alignment fittings and a horizontal packing clamp. Installation equipment kits contain components that are long lasting and often interchangeable with other sizes. Ordering installation equipment kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

KENMERKEN

Simplifies ordering

Used to splice different diameter bars

All components are designed for an extended life

SPECIFICATIES

Table 1/1


Catalogusnummer	Materiaal	Grootte rebar, metrisch	Formaat wapening, VS	Formaat rebar, Canada
RBW739810H	Staal, Graphite	32 mm, 25 mm	#10, #8	
RBW7391411H	Staal, Graphite	43 mm, 36 mm	#14, #11	45M, 35M
RBW7391811H	Staal, Graphite	57 mm, 36 mm	#18, #11	55M, 35M

AANVULLENDE PRODUCTGEGEVENS

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Components can also be purchased separately: (1) Pouring Basin Frame, (2) Crucible Chain Assembly, (3) Crucible Extension, (4) Crucible Cover, (5) End Alignment Fitting, and (6) Horizontal Packing Clamp.

DIAGRAMMEN

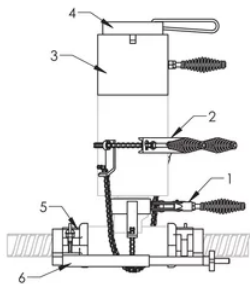

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische
ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE