

T-Series Vertical Transition Filler Material Kit



T-Series vertical filler material kits contain the following: Filler material, two vertical packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

KENMERKEN

Simplifies ordering

Used to splice different diameter bars

All components are for one-time use

SPECIFICATIES

Table 1/1

Catalogusnummer	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada
RBT911101B	36 mm, 28 mm	#11, #9	35M, 30M
RBT910101B	32 mm, 28 mm	#10, #9	
RBT1114101B	43 mm, 36 mm	#14, #11	45M, 35M
RBT1118101B	57 mm, 36 mm	#18, #11	55M, 35M
RBT1011101B	36 mm, 32 mm	#11, #10	
RBT1418101B	57 mm, 43 mm	#18, #14	55M, 45M

AANVULLENDE PRODUCTGEGEVENS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Vertical Top Packing, (3) Vertical Bottom Packing, (4) Pouring Basin Ceramic Guide Tube, and (5) Crucible Ceramic and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBT910101B	RBF105	RBS354712 RBS35475.5	RBS5037	RBS5038
RBT911101B	RBF125	RBS354714 RBS35476	RBS5037	RBS5038
RBT1011101B	RBF125	RBS354712 RBS35476	RBS5037	RBS5038
RBT1114101B	RBF125	RBS354715 RBS35476	RBS5037	RBS5039
RBT1118101B	RBF240	RBS354712 RBS354720	RBS5037	RBS5039
RBT1418101B	RBF195	RBS354720 RBS35477	RBS5037	RBS5039

DIAGRAMMEN

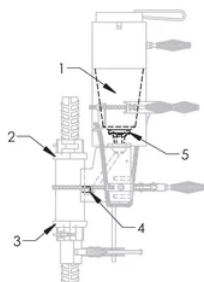

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische
ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE