


# Verticale overgangsmof van T-serie

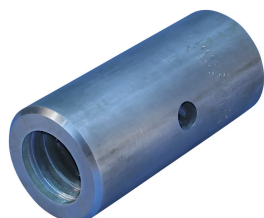

## KENMERKEN

Designed to connect vertical reinforcing bars and angular reinforcing bars greater than 45 degrees

Used to splice different diameter bars

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

## SPECIFICATIES

|                                 |                 |
|---------------------------------|-----------------|
| <b>Afwerking:</b>               | Gewoon          |
| <b>Huls:</b>                    | Standaardlengte |
| <b>Materiaal:</b>               | Staal           |
| <b>100% Amerikaanse inhoud:</b> | Ja              |

Table 1/2

| Catalogusnummer | Wapeningsmaat, metrisch | Wapeningsmaat, VS | Wapeningsmaat, Canada | Diameter 1 (Ø1) | Diameter 2 (Ø2) | Lengte 1 (L1) |
|-----------------|-------------------------|-------------------|-----------------------|-----------------|-----------------|---------------|
| RBT1114101A     | 43 mm, 36 mm            | #14, #11          | 45M, 35M              | 70 mm           | 52 mm           | 152 mm        |
| RBT1418101A     | 57 mm, 43 mm            | #18, #14          | 55M, 45M              | 86 mm           | 67 mm           | 165 mm        |

Table 2/2

| Catalogusnummer | Lengte 2 (L2) | Gewicht eenheid |
|-----------------|---------------|-----------------|
|-----------------|---------------|-----------------|


|             |       |         |
|-------------|-------|---------|
| RBT1114101A | 76 mm | 2.19 kg |
| RBT1418101A | 76 mm | 3.55 kg |

## AANVULLENDE PRODUCTGEGEVENS

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMMEN

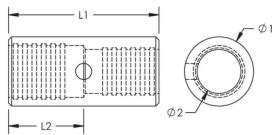

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

### Noord-Amerika

+1.800.753.9221  
optie 1 – Klantenservice  
optie 2 – Technische  
ondersteuning

### Europa

Nederland:  
+31 800-0200135  
Frankrijk:  
+33 800 901 793

### Europa

Duitsland:  
800 1890272  
andere landen:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Ons krachtige merkenportfolio:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**