


Front Panel, Unshielded, Bottom Hinged

Energiebedrijven

Unshielded front panel bottom hinged.

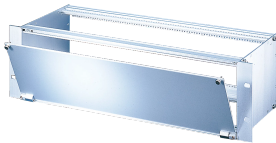

CERTIFICERINGEN



KENMERKEN

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPECIFICATIES

Table 1/3

Catalogusnummer	Rack Height	Rack Width	Package Quantity	Montage	Front Finish	Rear Finish
20838-271	3 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-272	3 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-273	3 U	84 HP	1	Hinged, Bottom	Anodized	Conductive

Catalogusnummer	Rack Height	Rack Width	Package Quantity	Montage	Front Finish	Rear Finish
20838-274	6 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-275	6 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-276	6 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-277	4 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-278	4 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-279	4 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-280	3 U	28 HP	1	Hinged, Bottom	Anodized	Conductive

Table 2/3

Catalogusnummer	Treated Edges	Voldoet aan	EMC Shielding	Hoogte	Materiaal	Product Type
20838-271	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	128.4 mm	Aluminium	Front Panel
20838-272	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	128.4 mm	Aluminium	Front Panel
20838-273	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	128.4 mm	Aluminium	Front Panel
20838-274	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	261.8 mm	Aluminium	Front Panel
20838-275	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	261.8 mm	Aluminium	Front Panel
20838-276	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	261.8 mm	Aluminium	Front Panel
20838-277	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	172.9 mm	Aluminium	Front Panel

Catalogusnummer	Treated Edges	Voldoet aan	EMC Shielding	Hoogte	Materiaal	Product Type
20838-278	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	172.9 mm	Aluminium	Front Panel
20838-279	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	172.9 mm	Aluminium	Front Panel
20838-280	Nee	IEC 60297-3-101, IEEE 1101.1/10	Nee	128.4 mm	Aluminium	Front Panel

Table 3/3

Catalogusnummer	Type	Breedte
20838-271	Front Panel without Handle	213 mm
20838-272	Front Panel without Handle	319.7 mm
20838-273	Front Panel without Handle	426.4 mm
20838-274	Front Panel without Handle	213 mm
20838-275	Front Panel without Handle	319.7 mm
20838-276	Front Panel without Handle	426.4 mm
20838-277	Front Panel without Handle	213 mm
20838-278	Front Panel without Handle	319.7 mm
20838-279	Front Panel without Handle	426.4 mm
20838-280	Front Panel without Handle	141.9 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE