


MultipacPRO 19" Chassis Basic Kit

Energiebedrijven

Such a kit enables a customer to configure the 3 different top / bottom covers.

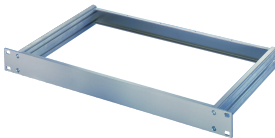

CERTIFICERINGEN



KENMERKEN

For non-standardized assemblies (1 ... 5 U) and standardized assemblies (1, 2 U) conforming to IEC 60297-3-105

Frame consists of two lateral parts and front/rear panel

Material: aluminium

Select further components (Accessories)

SPECIFICATIES

Table 1/2

Catalogusnummer	Rack Height	Diepte	Usable Width	Montage	Voldoet aan	EMC Shielding
20860-201	1 U	220 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-202	1 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)

Catalogusnummer	Rack Height	Diepte	Usable Width	Montage	Volddoet aan	EMC Shielding
20860-203	1 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-204	1 U	400 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-205	1 U	460 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-210	2 U	220 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-211	2 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-212	2 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-213	2 U	400 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-214	2 U	460 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-219	3 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-220	3 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-221	3 U	400 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-222	3 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-228	4 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-229	4 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-230	4 U	400 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-231	4 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-240	5 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)

Table 2/2

Catalogusnummer	Product Family	Product Type	Type	Certificeringen
-----------------	----------------	--------------	------	-----------------

20860-201	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-202	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-203	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-204	MultipacPRO	Subrack/Chassis	Configurable	
20860-205	MultipacPRO	Subrack/Chassis	Configurable	
20860-210	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-211	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-212	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-213	MultipacPRO	Subrack/Chassis	Configurable	
20860-214	MultipacPRO	Subrack/Chassis	Configurable	
20860-219	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-220	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-221	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-222	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-228	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-229	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-230	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-231	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-240	MultipacPRO	Subrack/Chassis	Configurable	RoHS

ADDITIONAL PRODUCT DETAILS

Please order mounting plate, cover and base plates, handles, telescopic slides separately.

Dimensions h = clear mounting height = H-8.1 mm, b = clear mounting width = 403 mm.

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE