


U-profile Front Panel, Shieldable, D-Sub Cutouts

Energiebedrijven

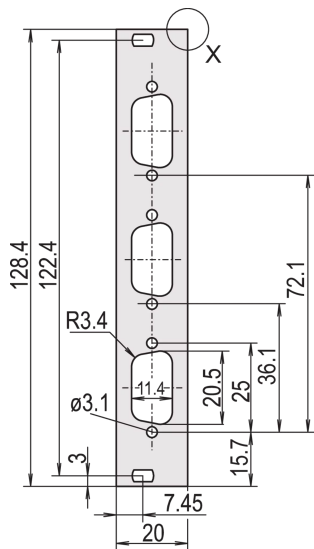

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICERINGEN



KENMERKEN

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFICATIES

Table 1/3

Catalogusnummer	Package Quantity	Montage	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-749	5	Screw-on Front	Textile	Anodized	Conductive	Nee

Catalogusnummer	Package Quantity	Montage	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-750	5	Screw-on Front	Textile	Anodized	Conductive	Nee
30849-751	5	Screw-on Front	Textile	Anodized	Conductive	Nee
30849-752	5	Screw-on Front	Textile	Anodized	Conductive	Nee
30849-753	5	Screw-on Front	Textile	Anodized	Conductive	Nee
30849-754	5	Screw-on Front	Textile	Anodized	Conductive	Nee
30849-755	5	Screw-on Front	Textile	Anodized	Conductive	Nee

Table 2/3

Catalogusnummer	Voldoet aan	EMC Shielding	Hoogte	Materiaal	Product Type	Rack Height
30849-749	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-750	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-751	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-752	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-753	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-754	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-755	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U

Table 3/3

Catalogusnummer	Rack Width	Type	Breedte
-----------------	------------	------	---------

30849-749	4 HP	Front Panel without Handle	20 mm
30849-750	4 HP	Front Panel without Handle	20 mm
30849-751	4 HP	Front Panel without Handle	20 mm
30849-752	4 HP	Front Panel without Handle	20 mm
30849-753	4 HP	Front Panel without Handle	20 mm
30849-754	4 HP	Front Panel without Handle	20 mm
30849-755	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE